

SAC-3P-24AWG-OE-OE-544-100,0SH - Cable reel



1317479

<https://www.phoenixcontact.com/us/products/1317479>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



By the meter, Cable reel, shielded, PVC, gray, 3-wire, color single wire: brown, blue, black, cable length: 100 m

Commercial data

Item number	1317479
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF16
Product key	AF1IIB
GTIN	4063151599911
Weight per piece (including packing)	22.22 g
Weight per piece (excluding packing)	22.22 g
Country of origin	US

SAC-3P-24AWG-OE-OE-544-100,0SH - Cable reel



1317479

<https://www.phoenixcontact.com/us/products/1317479>

Technical data

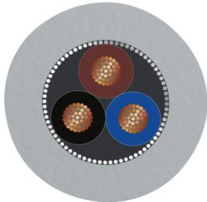
Product properties

Product type	Cable by the meter
Application	Connector
Number of positions	3

Cable/line

Cable length	100 m
--------------	-------

PVC gray 105 °C [544]

Dimensional drawing	
Cable weight	33 kg/km
UL AWM Style	2517 (105 °C / 300 V)
Number of positions	3
Shielded	yes
Cable type	PVC gray 105 °C [544]
Conductor structure signal line	7x 0.20 mm
AWG signal line	24
Wire diameter incl. insulation	1.12 mm ±0.03 mm
External cable diameter	4.70 mm ±0.2 mm
Outer sheath, material	PVC
External sheath, color	gray
Conductor material	Tin-plated Cu litz wires
Material wire insulation	PVC
Single wire, color	brown, blue, black
Overall twist	3 wires, twisted
Optical shield covering	85 %
Max. conductor resistance	max. 79.7 Ω/km (20 °C)
Insulation resistance	≥ (550 M Ohms/m @ 500V)
Nominal voltage, cable	300 V
Minimum bending radius, flexible installation	12 x D
Smallest bending radius, movable installation	57 mm
Flame resistance	FT1, VW-1
Other resistance	UV resistant
Ambient temperature (operation)	-30 °C ... 105 °C (cable, fixed installation)

SAC-3P-24AWG-OE-OE-544-100,0SH - Cable reel



1317479

<https://www.phoenixcontact.com/us/products/1317479>

	-5 °C ... 105 °C (Cable, flexible installation)
--	---

SAC-3P-24AWG-OE-OE-544-100,0SH - Cable reel



1317479

<https://www.phoenixcontact.com/us/products/1317479>

Classifications

ECLASS

ECLASS-13.0	27061801
-------------	----------

ETIM

ETIM 8.0	EC003249
----------	----------

SAC-3P-24AWG-OE-OE-544-100,0SH - Cable reel



1317479

<https://www.phoenixcontact.com/us/products/1317479>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com