

# HC-STA-D07-BWSCF-EL-AL - Housing



1419251  
<https://www.phoenixcontact.com/us/products/1419251>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Panel mounting base D7, with single locking latch, material: Die-cast aluminum, salt water resistant, protective cover material: PA, height: 25.5 mm, cable gland: none, protective cover: yes, Standard, for socket inserts

## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1419251       |
| Packing unit                         | 1 pc          |
| Minimum order quantity               | 1 pc          |
| Sales key                            | BF56          |
| Product key                          | AF7APF        |
| GTIN                                 | 4055626159829 |
| Weight per piece (including packing) | 26.8 g        |
| Weight per piece (excluding packing) | 26.8 g        |
| Customs tariff number                | 85389099      |
| Country of origin                    | CN            |

# HC-STA-D07-BWSCF-EL-AL - Housing



1419251

<https://www.phoenixcontact.com/us/products/1419251>

## Technical data

 
### Notes

|         |                                                                         |
|---------|-------------------------------------------------------------------------|
| General | for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12 |
|---------|-------------------------------------------------------------------------|

### Product properties

|                     |                            |
|---------------------|----------------------------|
| Product type        | Housing with locking latch |
| Housing type        | Panel mounting base        |
| Product family      | HC-STA-D07                 |
| Application         | Standard                   |
| Type                | D7                         |
| Protective cover    | yes                        |
| Shielded            | no                         |
| Pg screw connection | none                       |

### Dimensions

|                     |                                                                                      |
|---------------------|--------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width               | 34.2 mm                                                                              |
| Height              | 25.5 mm                                                                              |
| Length              | 24.2 mm                                                                              |
| Hole diameter       | 3.2 mm                                                                               |

### Installation dimensions

|                               |       |
|-------------------------------|-------|
| Width of the assembly cutout  | 21 mm |
| Length of the assembly cutout | 21 mm |

### Material specifications

|                                        |                                         |
|----------------------------------------|-----------------------------------------|
| Flammability rating according to UL 94 | V0 (Interlock)                          |
|                                        | V0 (Protective cover)                   |
| Seal material Flat gasket              | NBR, conductive                         |
| Seal material Profile gasket           | NBR                                     |
| Housing material                       | Die-cast aluminum, salt water resistant |
| Housing surface material               | uncoated                                |
| Material, protective cover             | PA                                      |
| Locking latch material                 | PA                                      |

### Mechanical properties

#### Mechanical data

|              |       |
|--------------|-------|
| Locking type | Latch |
|--------------|-------|

# HC-STA-D07-BWSCF-EL-AL - Housing



1419251

<https://www.phoenixcontact.com/us/products/1419251>

## Connection data

|                   |                                                                    |
|-------------------|--------------------------------------------------------------------|
| Tightening torque | 0.5 Nm ... 0.8 Nm (For M3 mounting screws on the panel-mount base) |
|-------------------|--------------------------------------------------------------------|

## Mounting

|               |                             |
|---------------|-----------------------------|
| Assembly note | For mounting socket inserts |
|---------------|-----------------------------|

## Environmental and real-life conditions

### Ambient conditions

|                                 |                                     |
|---------------------------------|-------------------------------------|
| Degree of protection            | IP66 (with locked protective cover) |
|                                 | IP67 (when plugged in)              |
| Enclosure rating (NEMA)         | 4 (UL 50e)                          |
|                                 | 4X (UL 50e)                         |
| Impact strength                 | IK06                                |
| Ambient temperature (operation) | -40 °C ... 125 °C                   |

# HC-STA-D07-BWSCF-EL-AL - Housing


1419251

<https://www.phoenixcontact.com/us/products/1419251>



## Drawings

Dimensional drawing

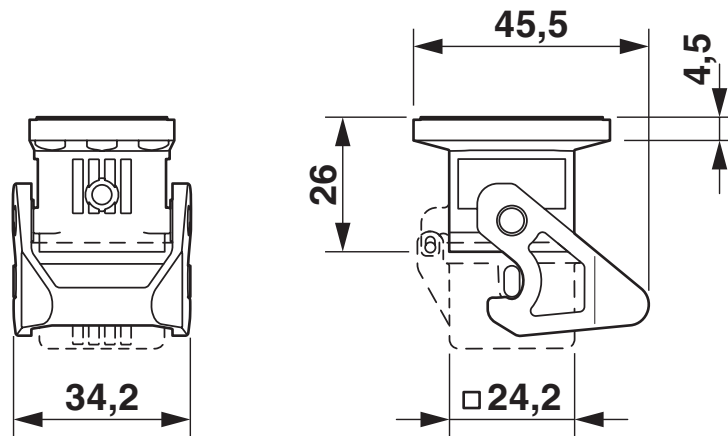

Dimensional drawing


# HC-STA-D07-BWSCF-EL-AL - Housing

1419251


<https://www.phoenixcontact.com/us/products/1419251>



Dimensional drawing

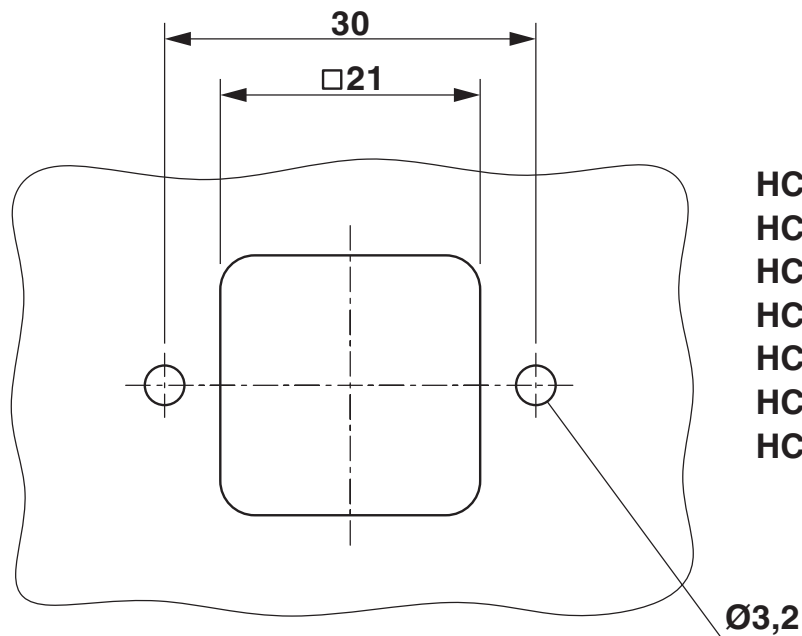

HC-A03  
HC-A04  
HC-D07  
HC-D08  
HC-Q05  
HC-Q07  
HC-Q12

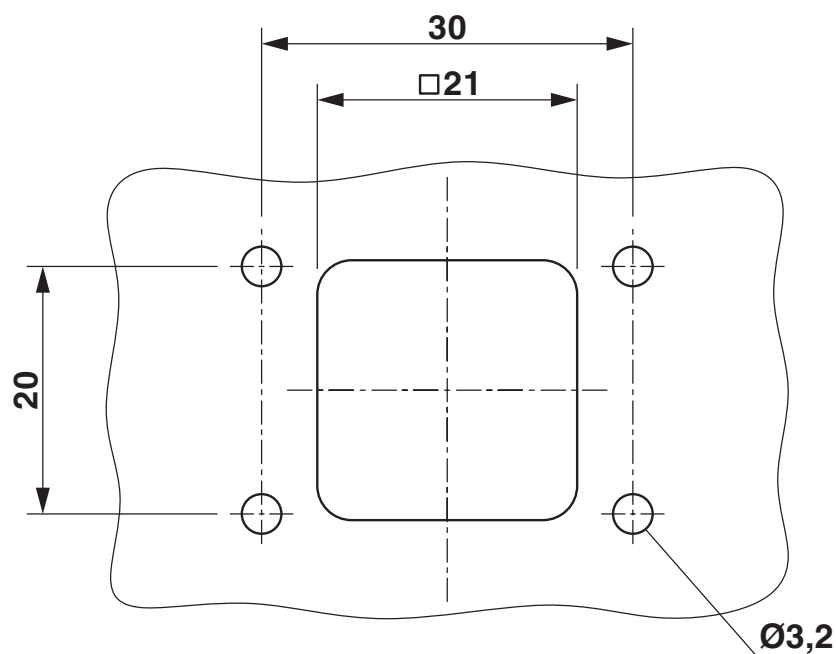

HC-Q02  
HC-Q03  
HC-Q04

Mounting cutout

# HC-STA-D07-BWSCF-EL-AL - Housing



1419251

<https://www.phoenixcontact.com/us/products/1419251>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1419251>

**DNV**  
Approval ID: TAE000037S

**cUL Recognized**  
Approval ID: E255026

**UL Recognized**  
Approval ID: E255026

# HC-STA-D07-BWSCF-EL-AL - Housing



1419251

<https://www.phoenixcontact.com/us/products/1419251>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27440202 |
| ECLASS-15.0 | 27440202 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000437 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

Environmental product compliance

|                                         |                                          |
|-----------------------------------------|------------------------------------------|
| EU RoHS                                 |                                          |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |                                          |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|                                         | No hazardous substances above the limits |
| EU REACH SVHC                           |                                          |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |