

# CES-B24-WRG-BK - Flat gasket

0801727

<https://www.phoenixcontact.com/us/products/0801727>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Flat gasket made of NBR, size B24



## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 0801727       |
| Packing unit                         | 10 pc         |
| Minimum order quantity               | 1 pc          |
| Sales key                            | BF67          |
| Product key                          | AF7CZX        |
| GTIN                                 | 4046356675260 |
| Weight per piece (including packing) | 13 g          |
| Weight per piece (excluding packing) | 3.24 g        |
| Customs tariff number                | 40169300      |
| Country of origin                    | DE            |

# CES-B24-WRG-BK - Flat gasket

0801727

<https://www.phoenixcontact.com/us/products/0801727>



## Technical data

### Product properties

|              |      |
|--------------|------|
| Product type | Seal |
| Type         | B24  |

### Dimensions

| Dimensional drawing             |         |
|---------------------------------|---------|
|                                 |         |
| Width                           | 57.5 mm |
| Height                          | 2.5 mm  |
| Length                          | 147 mm  |
| Drill hole distance, horizontal | 130 mm  |
| Drill hole distance, vertical   | 32 mm   |
| Hole diameter                   | 4.5 mm  |

### Material specifications

|               |     |
|---------------|-----|
| Seal material | NBR |
|---------------|-----|

### Environmental and real-life conditions

| Ambient conditions              |                           |
|---------------------------------|---------------------------|
| Ambient temperature (operation) | -20 °C ... 80 °C (static) |

# CES-B24-WRG-BK - Flat gasket


0801727

<https://www.phoenixcontact.com/us/products/0801727>



## Drawings

Dimensional drawing

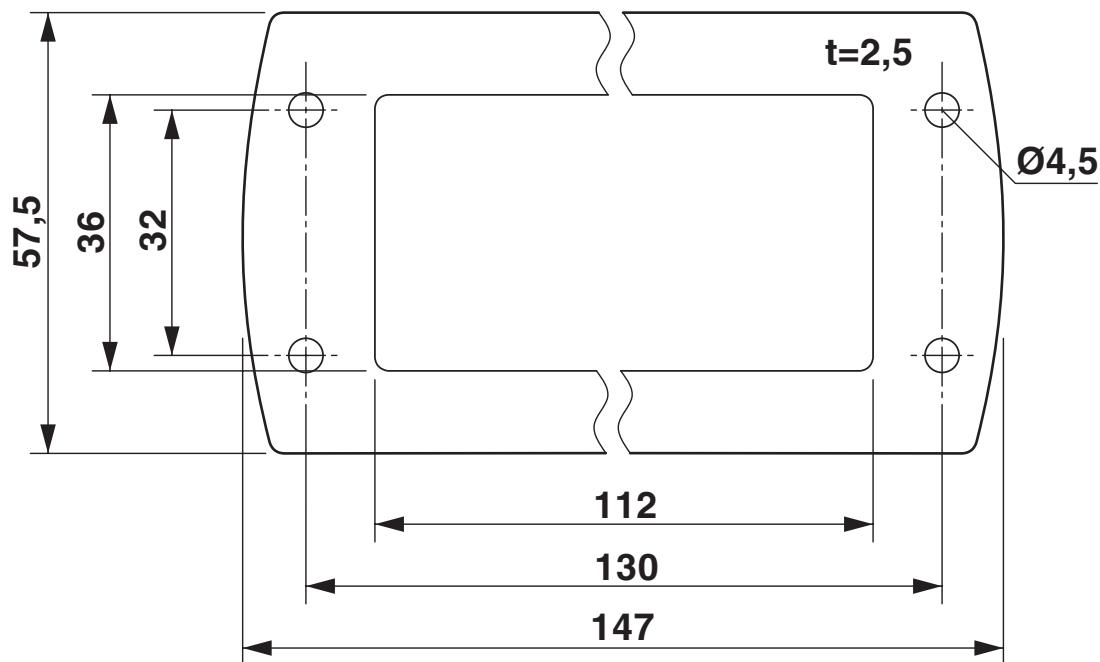

Dimensional drawing

# CES-B24-WRG-BK - Flat gasket

0801727

<https://www.phoenixcontact.com/us/products/0801727>



## Approvals

ⓘ To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/0801727>

**DNV**

Approval ID: TAE00003VJ

# CES-B24-WRG-BK - Flat gasket

0801727

<https://www.phoenixcontact.com/us/products/0801727>



## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 23071590 |
| ECLASS-15.0 | 23071590 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC002498 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31401600 |
|-------------|----------|

# CES-B24-WRG-BK - Flat gasket

0801727

<https://www.phoenixcontact.com/us/products/0801727>



## Environmental product compliance

### EU RoHS

|   |                    |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

### China RoHS

|  |  |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|  | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

### EF3.0 Climate Change

|         |               |
|---------|---------------|
| CO2e kg | 0.582 kg CO2e |
|---------|---------------|

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA

586 Fulling Mill Road

Middletown, PA 17057, United States

(+717) 944-1300

[info@phoenixcon.com](mailto:info@phoenixcon.com)