

# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Thermal transfer printer with internal rewinder for printing all materials in roll format with a print resolution of 300 dpi. Suitable for long-term use in production and for large print volumes, as large rolls can also be processed.

## Product description

Benefit from the flexibility of the THERMOMARK E.300 D industrial printer:

Use the printer to print all roll materials in the MARKING system portfolio for professional and durable wire and cable identification, equipment and plant identification, and terminal identification.

In addition to prepunched label formats, you can also process shrink sleeve as well as label material in continuous format. To do this, simply combine the printer with the THERMOMARK E.CUTTER or E.CUTTER/P for the convenient cutting or perforation of materials in continuous format.

For the maximum efficiency of identification processes, combine the standard printer with a THERMOMARK E SERIES applicator. This will transform your printer into an efficient printing and application system, enabling you to achieve an average time saving of 60% as the markers are printed and applied in just one automated process step. With the THERMOMARK E.300 D, the THERMOMARK E.WRAP, E.WIRE, and E.SLEEVE applicators can be used for efficient wire and cable identification and the THERMOMARK E.VARIO can be used for efficient terminal identification.

Scope of supply:

THERMOMARK E.300 D, power cable (pin connector pattern: type "B"), USB cable, EML (20X8)R/TL label roll (0802999), THERMOMARK-RIBBON 110/50 ink ribbon (0800687), multilingual packing slip

## Your advantages

- Suitable for all roll materials in the MARKING system product portfolio
- The THERMOMARK E.300 D can process larger material rolls than the THERMOMARK ROLL 2.0
- Continuous media in roll format can be easily cut or perforated using the THERMOMARK E.CUTTER (for cutting label material in continuous format) or the THERMOMARK E.CUTTER/P (for perforating shrink sleeve in continuous format)
- Easily transform the standard printer into an efficient printing and application system: Compatibility with all THERMOMARK E SERIES applicators
- When operating the printer with an applicator for wire and cable identification, convenient and intuitive project processing is possible directly via the 4.3" multicolor LCD touch display; the user also receives structured guidance and is supplied with the relevant information
- Easy handling of all status and error messages, as corresponding videos can be accessed and played directly via the touch display
- Status messages are conveniently sent in real time and bidirectionally to the marking software with OPC UA when operating the printer via the Ethernet interface
- The 300 dpi print resolution is the absolute industry standard for all conventional applications and materials
- Efficient and maintenance-free operation with proven thermal transfer printing technology
- Easy to control and manage with MARKING system software

## Commercial data

Item number	1287033
Packing unit	1 pc
Minimum order quantity	1 pc

# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



Sales key	BG01
Product key	BG1221
GTIN	4063151493684
Weight per piece (including packing)	12,800 g
Weight per piece (excluding packing)	9,780 g
Customs tariff number	84433210
Country of origin	DE

# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## Technical data

### Product properties

Product type	Marking system
Scope of supply	Ink ribbon, label roll, power cable, USB cable, operating instructions
	Power cable, USB cable, operating instructions, label roll, ink ribbon

### Marking

Identification technology	Thermotransfer
---------------------------	----------------

### Device properties

Print width	105 mm
Print resolution	300 dpi
Operating system	Windows 10, Windows 11, Windows Server 2016, Windows Server 2019, Windows Server 2022

### Electrical properties

#### Supply

Supply voltage range	100 V AC ... 240 V AC (50 Hz ... 60 Hz)
----------------------	---

### Dimensions

Width	252 mm
Height	288 mm
Length	460 mm

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	5 °C ... 40 °C
---------------------------------	----------------

# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## Classifications

### ECLASS

ECLASS-13.0	19140104
ECLASS-15.0	19140104

### ETIM

ETIM 9.0	EC001684
----------	----------

# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

## Accessories

### THERMOMARK E.WIRE - Applicator

1203216

<https://www.phoenixcontact.com/us/products/1203216>



Applicator for the efficient printing and application of movable E-WM... markers on wires and cables in a single automated process step

### THERMOMARK E.SLEEVE - Applicator

1192932

<https://www.phoenixcontact.com/us/products/1192932>



Applicator for the efficient printing and application of E-WMS... shrink sleeves and marking sleeves on wires and cables in a single automated process step

# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## THERMOMARK E.WRAP - Applicator

1192931

<https://www.phoenixcontact.com/us/products/1192931>



Applicator for the efficient printing and applying of E-WML... wire-wrap labels on wires and cables in a single automated process step

## THERMOMARK E.CUTTER - Cutter

1234241

<https://www.phoenixcontact.com/us/products/1234241>

Cutter for marking materials in continuous format for cutting custom lengths



# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

## THERMOMARK E.CUTTER/P - Cutter

1201336

<https://www.phoenixcontact.com/us/products/1201336>

Perforation cutter for all shrink sleeve and marking sleeve versions in continuous format for cutting custom lengths



## THERMOMARK-RIBBON 110 - Ink ribbon

5145384

<https://www.phoenixcontact.com/us/products/5145384>



Ink ribbon, for roll printers for printing product groups TML..., TMT..., WML..., WML HF..., WML-FLAG..., WMT..., WMTB..., EML..., EMLC ..., EML-ESD..., EMLF ..., EML-HA ..., EML-LPR(D) ..., EML-LT ..., EMLP..., EML-RM..., EML-RS ..., EMLS..., EMT..., PML-GHS..., PML-T..., PML-P..., PML-W..., PMM..., length: 300 m, roll length: 300 m, width: 110 mm, color: black

# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## THERMOMARK-RIBBON 110 BU - Ink ribbon

0829544

<https://www.phoenixcontact.com/us/products/0829544>

Ink ribbon, length: 300 m, roll length: 300 m, width: 110 mm, color: blue



## THERMOMARK-RIBBON 110 GN - Ink ribbon

0829542

<https://www.phoenixcontact.com/us/products/0829542>

Ink ribbon, length: 300 m, roll length: 300 m, width: 110 mm, color: green



# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## THERMOMARK-RIBBON 110 RD - Ink ribbon

0829543

<https://www.phoenixcontact.com/us/products/0829543>

Ink ribbon, length: 300 m, roll length: 300 m, width: 110 mm, color: red



## THERMOMARK-RIBBON 110/50 - Ink ribbon

0800687

<https://www.phoenixcontact.com/us/products/0800687>

Ink ribbon, for roll printers for printing product groups TML..., TMT..., WML..., WML HF..., WML-FLAG..., WMT..., WMTB..., EML..., EMLC ..., EML-ESD..., EMLF ..., EML-HA ..., EML-LPR(D) ..., EML-LT ..., EMLP..., EML-RM..., EML-RS ..., EMLS..., EMT..., PML-GHS..., PML-T..., PML-P..., PML-W..., PMM..., length: 50 m, roll length: 50 m, width: 110 mm, color: black



# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## THERMOMARK-RIBBON 110-EML-HT - Ink ribbon

0800342

<https://www.phoenixcontact.com/us/products/0800342>

Ink ribbon, for roll printer for printing product group EML-HT..., length: 300 m, roll length: 300 m, width: 110 mm, color: black



---

## THERMOMARK-RIBBON 110-WMS - Ink ribbon

5145397

<https://www.phoenixcontact.com/us/products/5145397>

Ribbon sheet, length: 300 m, width: 110 mm, printing color: Black (specially for shrinking sleeves)



# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## THERMOMARK-RIBBON 110-WMSU - Ink ribbon

0801358

<https://www.phoenixcontact.com/us/products/0801358>



Ink ribbon, For roll printer for printing product groups WMS..., WMS-2 HF..., and WMTB HF-HP, length: 300 m, roll length: 300 m, width: 110 mm, color: black

---

## THERMOMARK-RIBBON 110-WMSU WH - Ink ribbon

0801359

<https://www.phoenixcontact.com/us/products/0801359>



Ink ribbon, for roll printer for printing product group WMS... (black), length: 300 m, roll length: 300 m, width: 110 mm, color: white

---

# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

## THERMOMARK-RIBBON 110-WMTB HF - Ink ribbon

5148007

<https://www.phoenixcontact.com/us/products/5148007>



Ink ribbon, for roll printers for printing product groups WMTB HF..., WMS-2 HF..., length: 300 m, roll length: 300 m, width: 110 mm, color: black

---

## THERMOMARK-RIBBON 25-WMSU - Ink ribbon

0803390

<https://www.phoenixcontact.com/us/products/0803390>



Ink ribbon, for roll printer for printing product groups WMS... and WMS-2 HF..., length: 300 m, roll length: 300 m, width: 25 mm, color: black

# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## THERMOMARK-RIBBON 64-WMSE - Ink ribbon

5145724

<https://www.phoenixcontact.com/us/products/5145724>

Ink ribbon, for roll printer for printing product group WMS..., length: 300 m, roll length: 300 m, width: 64 mm, color: black



---

## THERMOMARK-RIBBON 64-WMSE RD - Ink ribbon

5145740

<https://www.phoenixcontact.com/us/products/5145740>

Ink ribbon, length: 300 m, roll length: 300 m, width: 64 mm, color: red



# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## THERMOMARK-RIBBON 64-WMSU - Ink ribbon

0801360

<https://www.phoenixcontact.com/us/products/0801360>



Ink ribbon, for roll printer for printing product groups WMS... and WMS-2 HF..., length: 300 m, roll length: 300 m, width: 64 mm, color: black

---

## THERMOMARK-RIBBON 64-WMSU WH - Ink ribbon

0801361

<https://www.phoenixcontact.com/us/products/0801361>



Ink ribbon, for roll printer for printing product group WMS... (black), length: 300 m, roll length: 300 m, width: 64 mm, color: white

# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

## TM-RIBBON 105 BK 106 - Ink ribbon

1255597

<https://www.phoenixcontact.com/us/products/1255597>



Ink ribbon, for roll printer for printing product groups WMTB HF-D, length: 0.3 m, roll length: 300 m, width: 105 mm, color: black

---

## TM-RIBBON 110 WH 100 - Ink ribbon

0804661

<https://www.phoenixcontact.com/us/products/0804661>



Ink ribbon, For THERMOMARK roll printers and THERMOMARK CARD for printing material-off-the-roll product groups: EML ..., EMLP ..., EMLF ..., PML-M . ., WMTB HF-HP..., WMS-2 HF ... RD and US-material product groups: US-EML(S)P ..., US-EMLP-HA ..., US-EM(S)P ..., US-WMT ..., US-WMTB ..., US-PML-M ..., US-EMLF ..., roll length: 60 m, width: 110 mm, color: white

# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## TM-RIBBON 110 WH 101 - Ink ribbon

1099966

<https://www.phoenixcontact.com/us/products/1099966>



Ink ribbon, For THERMOMARK roll printers for printing the product group material off the roll: PML-T..., roll length: 60 m, width: 110 mm, color: white

---

## TM-RIBBON 110-EX - Ink ribbon

0803211

<https://www.phoenixcontact.com/us/products/0803211>



Ink ribbon, for roll printer for printing product group EML-EX..., roll length: 280 m, width: 110 mm, color: black

---

# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## TM-RIBBON 110-WMTB HF WH - Ink ribbon

0802990

<https://www.phoenixcontact.com/us/products/0802990>



Ink ribbon, for roll printer for printing product group WMTB HF..., length: 300 m, roll length: 300 m, width: 110 mm, color: white

---

## TM-RIBBON 25 BK 102 - Ink ribbon

1053499

<https://www.phoenixcontact.com/us/products/1053499>



Ink ribbon, for printing WMS-OT/WMS-2 HF... materials, length: 300 m, roll length: 300 m, width: 25 mm, color: black

# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

## TM-RIBBON 30 BK 103 - Ink ribbon

1309076

<https://www.phoenixcontact.com/us/products/1309076>



Ink ribbon, for the E-WM... product group in combination with the THERMOMARK E.WIRE applicator, length: 300 m, roll length: 300 m, width: 30 mm, color: black

## TM-RIBBON 40 BK 105 - Ink ribbon

1259008

<https://www.phoenixcontact.com/us/products/1259008>



Ink ribbon, for the E-WMS... product group in combination with the THERMOMARK E.SLEEVE applicator and the WMS... and WMS-2 HF... product groups in combination with conventional roll printers, length: 300 m, roll length: 300 m, width: 40 mm, color: black

# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

## TM-RIBBON 64 BK 103 - Ink ribbon

1255598

<https://www.phoenixcontact.com/us/products/1255598>



Ink ribbon, For the E-WML... product group in combination with the THERMOMARK E.WRAP applicator, length: 300 m, roll length: 300 m, width: 64 mm, color: black

---

## TRM-PRESSURE ROLLER STANDARD - Pressure roller

0804655

<https://www.phoenixcontact.com/us/products/0804655>

Standard pressure roller



# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

## TRM-PRESSURE ROLLER 4-50 - Pressure roller

0804656

<https://www.phoenixcontact.com/us/products/0804656>

Pressure roller for continuous shrink sleeve



---

## TM E.WIRE/E.SLEEVE-PR - Pressure roller

1259203

<https://www.phoenixcontact.com/us/products/1259203>

Pressure roller for all E-WM... and E-WMS... materials (for material width of up to 30 mm/1.18")



# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

## TM E.WRAP-PR - Pressure roller

1259200

<https://www.phoenixcontact.com/us/products/1259200>

Pressure roller for all E-WML... materials (material width of up to 60 mm/2.36")



---

## TM E.300/E.600-TEAR OFF PLATE - Demolition plate

1263118

<https://www.phoenixcontact.com/us/products/1263118>

Tear-off plate for all roll printers in the THERMOMARK E SERIES



# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

## TM E.300/E.600-DISPENSING EDGE/L - Dispensing edge

1263116

<https://www.phoenixcontact.com/us/products/1263116>

Dispensing edge for processing all E-WML... materials when using the  
THERMOMARK E.WRAP



---

## TM E.300/E.600-FRONT COVER - Front plate

1285305

<https://www.phoenixcontact.com/us/products/1285305>

Front panel for all roll printers in the THERMOMARK E SERIES



# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## THERMOMARK ROLL-ERH - Media hub

5146448

<https://www.phoenixcontact.com/us/products/5146448>

External media hub, for the THERMOMARK ROLL, for roll diameter of 150 to 400 mm



---

## THERMOMARK-ERH 500 - Media hub

5146309

<https://www.phoenixcontact.com/us/products/5146309>

External media hub, for the THERMOMARK ROLL, for roll diameter of up to 500 mm



# THERMOMARK E.300 D US - Thermal transfer printer

1287033

<https://www.phoenixcontact.com/us/products/1287033>



## THERMOMARK-CP - Accessories

5145371

<https://www.phoenixcontact.com/us/products/5145371>

Cleaning pen, for thermal transfer printers



## CLEANING STICK - Cleaning pen

5146697

<https://www.phoenixcontact.com/us/products/5146697>

Cleaning stick for fast and efficient printhead cleaning of all Phoenix Contact thermal transfer printers.



# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

## TRM-MARGIN STOP - Locking

0804657

<https://www.phoenixcontact.com/us/products/0804657>

Locking



## THERMOMARK ROLLMASTER-CASE - Case

0804643

<https://www.phoenixcontact.com/us/products/0804643>

Transport case for THERMOMARK ROLLMASTER and THERMOMARK E SERIES printers



# THERMOMARK E.300 D US - Thermal transfer printer



1287033

<https://www.phoenixcontact.com/us/products/1287033>

## MARKING SYSTEM SOFTWARE - Software

1669297

<https://www.phoenixcontact.com/us/products/1669297>

Create marking files easily and conveniently on your laptop or desktop PC. All Phoenix Contact marking systems as well as standard office printers can be controlled via the software. The software is available for download.




## PROJECT COMPLETE - Software

1050453

<https://www.phoenixcontact.com/us/products/1050453>

Intuitive planning and marking software for configuring terminal strips and for professional marking of marking materials for terminal blocks, conductors, cables, devices, and systems. The software is available for download

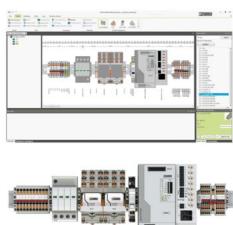

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)