

A-INL-M40-P-BK - Counter nut

1411218

<https://www.phoenixcontact.com/us/products/1411218>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Counter nut, for threads M40 x 1.5, color: jet black



Commercial data

Item number	1411218
Packing unit	5 pc
Minimum order quantity	1 pc
Sales key	BF68
Product key	AF7DZX
GTIN	4046356923507
Weight per piece (including packing)	8.1 g
Weight per piece (excluding packing)	7.47 g
Customs tariff number	39269097
Country of origin	TR

A-INL-M40-P-BK - Counter nut

1411218


<https://www.phoenixcontact.com/us/products/1411218>

Technical data

Product properties

Product type	Flat nut
Thread type	M40

Dimensions

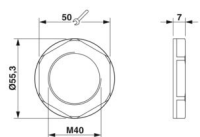Dimensional drawing	
Length	7 mm
Diameter	40 mm
Connecting thread diameter	40 mm
Wrench size, counter nut	50 mm
Hexagon angular dimension	55.3 mm
Thread type connection side	M40 x 1.5
Thread pitch	1.5 mm

Material specifications

Material	PA
Flammability rating according to UL 94	V2

Cable/line

Halogen-free	yes
--------------	-----

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 100 °C
---------------------------------	-------------------

A-INL-M40-P-BK - Counter nut


1411218

<https://www.phoenixcontact.com/us/products/1411218>



Drawings

Dimensional drawing

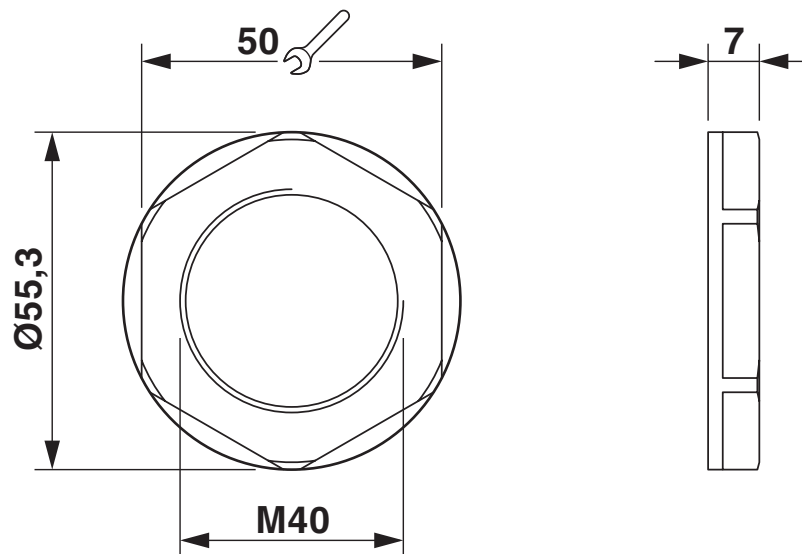

A-INL-M40-P-BK - Counter nut



1411218

<https://www.phoenixcontact.com/us/products/1411218>

Classifications

ECLASS

ECLASS-13.0	27140807
ECLASS-15.0	27140807

ETIM

ETIM 9.0	EC000879
----------	----------

UNSPSC

UNSPSC 21.0	31161700
-------------	----------

A-INL-M40-P-BK - Counter nut



1411218
<https://www.phoenixcontact.com/us/products/1411218>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com