

# HC-B-GB-M25-PLRBK - Cable gland

1414661

<https://www.phoenixcontact.com/us/products/1414661>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Set consisting of: EVO plastic adapter 1414244 and plastic screw connection with bending armor rod 1415180, M25



## Commercial data

Item number	1414661
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF57
Product key	AF7APL
GTIN	4055626031125
Weight per piece (including packing)	55.2 g
Weight per piece (excluding packing)	54.957 g
Customs tariff number	39269097
Country of origin	PL

# HC-B-GB-M25-PLRBK - Cable gland

1414661

<https://www.phoenixcontact.com/us/products/1414661>



## Technical data

### Product properties

Product type	Cable screw gland
No. of conductors	1
Type of the screw connection	M25
Shielded	no
Execution of the strain relief	A

### Dimensions

Dimensional drawing	
Wrench size, union nut	29 mm
Wrench size, support	29 mm
Thread pitch	1.5 mm

### Material specifications

Color	black (RAL 9005)
Seal material	EPDM
Seal material O-ring	NBR
Housing material	PA
Material for screw connection	PA

### Cable/line

External cable diameter Cable 1	9 mm ... 17 mm
---------------------------------	----------------

### Environmental and real-life conditions

Ambient conditions	
Degree of protection	IP66
Ambient temperature (operation)	-40 °C ... 100 °C

# HC-B-GB-M25-PLRBK - Cable gland




1414661

<https://www.phoenixcontact.com/us/products/1414661>

## Drawings

Dimensional drawing

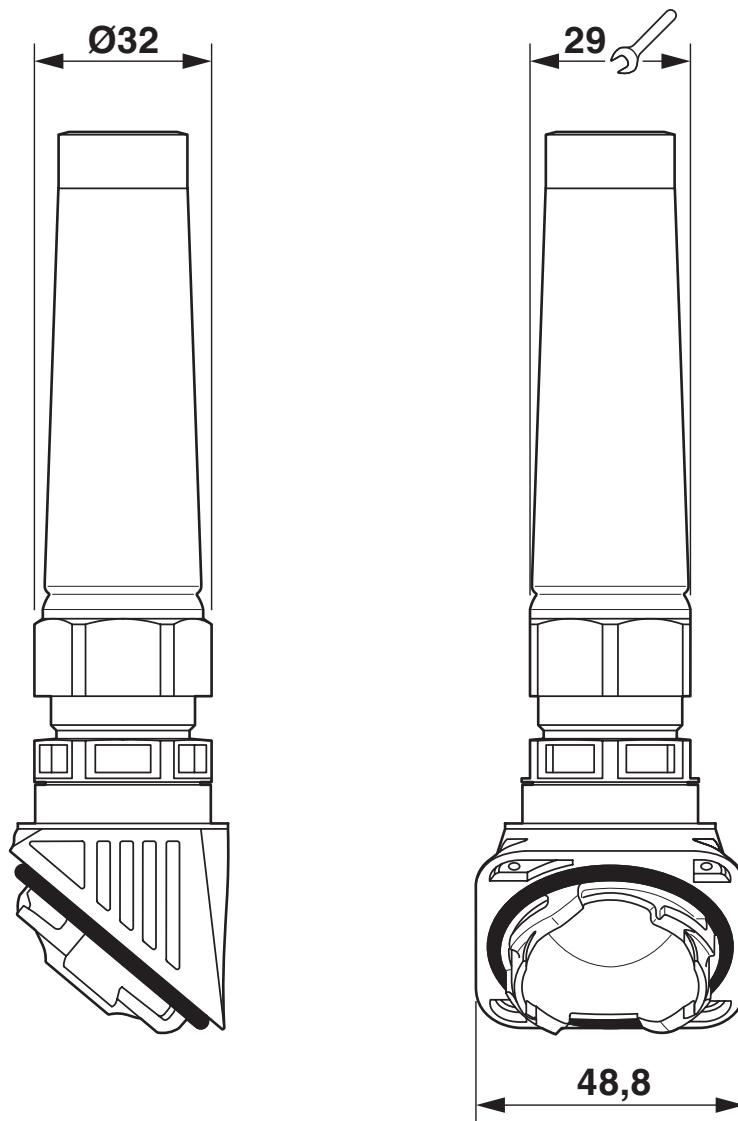

Dimensional drawing

# HC-B-GB-M25-PLRBK - Cable gland

1414661

<https://www.phoenixcontact.com/us/products/1414661>



## Approvals

ⓘ To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1414661>



**EAC**

Approval ID: RU C-DE.AI30.B.01102



**EAC-RoHS**

Approval ID: RU D-DE.HB35.B.00387

# HC-B-GB-M25-PLRBK - Cable gland

1414661

<https://www.phoenixcontact.com/us/products/1414661>



## Classifications

### ECLASS

ECLASS-13.0	27140801
ECLASS-15.0	27140801

### ETIM

ETIM 9.0	EC000441
----------	----------

### UNSPSC

UNSPSC 21.0	39121300
-------------	----------

# HC-B-GB-M25-PLRBK - Cable gland

1414661

<https://www.phoenixcontact.com/us/products/1414661>



## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

### EF3.0 Climate Change

CO2e kg	0.395 kg CO2e
---------	---------------

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA

586 Fulling Mill Road

Middletown, PA 17057, United States

(+717) 944-1300

[info@phoenixcon.com](mailto:info@phoenixcon.com)