

VS-09-BU-DSUB-2P-LH - D-SUB contact support

1655289

<https://www.phoenixcontact.com/us/products/1655289>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

D-SUB contact carrier, shell size 1, accommodation for two combined contacts, type of contact socket, fixing with 4-40 UNC thread and solder pins, for panel mounting frame VS-09-...



Your advantages

- Compatible with IP67 sleeve housing and panel-mount frame
- Easy assembly

Commercial data

Item number	1655289
Packing unit	50 pc
Minimum order quantity	1 pc
Sales key	AB19
Product key	ABNCAB
GTIN	4046356029223
Weight per piece (including packing)	10.09 g
Weight per piece (excluding packing)	10.09 g
Customs tariff number	85366990
Country of origin	DE

VS-09-BU-DSUB-2P-LH - D-SUB contact support

1655289

<https://www.phoenixcontact.com/us/products/1655289>



Technical data

Notes

Order information:	The contacts must be ordered separately since they are not included in the scope of supply of the contact carriers. Both one male and one female contact must be mounted in the contact carrier.
--------------------	--

Product properties

Product type	Contact insert
Application	Combination contact insert
Type	D-SUB
Number of positions	2
Connection profile	D-SUB
Number of slots	1
Shielded	yes

Electrical properties

Transmission medium	Copper
---------------------	--------

Connection data

Connection method	Wave soldering contacts
-------------------	-------------------------

Dimensions

Width	21.6 mm
Height	17.1 mm
Length	31.19 mm

Material specifications

Flammability rating according to UL 94	V0
Housing material	Metal
Housing surface material	metal-plated
Contact surface material	Gold
Contact carrier material	PBT

Mechanical properties

Mechanical data	
Insertion/withdrawal cycles	≥ 500

Environmental and real-life conditions

Ambient conditions	
Degree of protection	IP20
Ambient temperature (operation)	-55 °C ... 125 °C

Mounting

Mounting type


Screw mounting

1655289

<https://www.phoenixcontact.com/us/products/1655289>

Drawings

Drilling plan/solder pad geometry

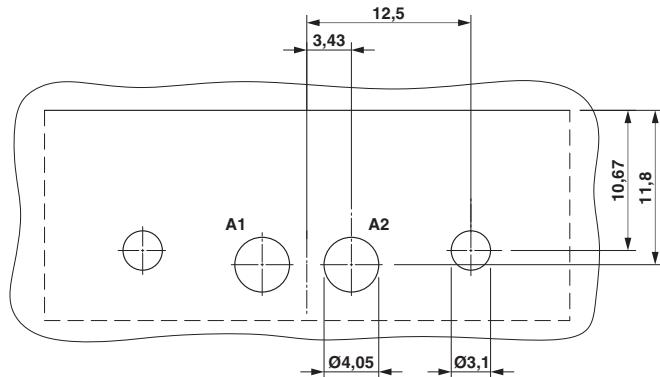

Drilling diagram

VS-09-BU-DSUB-2P-LH - D-SUB contact support

1655289

<https://www.phoenixcontact.com/us/products/1655289>



Approvals

ⓘ To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1655289>



UL Recognized

Approval ID: E118976

Classifications

ECLASS

ECLASS-13.0	27440302
ECLASS-15.0	27440323

ETIM

ETIM 9.0	EC001132
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

VS-09-BU-DSUB-2P-LH - D-SUB contact support

1655289

<https://www.phoenixcontact.com/us/products/1655289>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(a), 6(a)-I, 6(c)

China RoHS

Environment friendly use period (EFUP)	EFUP-50
An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.	

EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	bb14764f-0d96-43c1-8a5a-8ad58cbc0632

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA

586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com