

SAC-5P-M12YF/2XM12FS VP - Y distributor



1698013

<https://www.phoenixcontact.com/us/products/1698013>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Y distributor, 5-position, Socket straight M12, coding: A, on Socket straight M12, coding: A and Socket straight M12, coding: A, Parallel distributor

Commercial data

Item number	1698013
Packing unit	5 pc
Minimum order quantity	5 pc
Sales key	BF10
Product key	AF1GAB
GTIN	4017918198138
Weight per piece (including packing)	32.6 g
Weight per piece (excluding packing)	29.4 g
Customs tariff number	85366990
Country of origin	DE

Technical data

Product properties

Product type	Y-distributor
Number of positions	5
Coding	A

Insulation characteristics

Overvoltage category	II
Degree of pollution	3

Electrical properties

Insulation resistance	$\geq 100 \text{ M}\Omega$
-----------------------	----------------------------

Signaling

Status display	no
Status display present	no

Material specifications

Flammability rating according to UL 94	HB
Seal material	NBR
Material of grip body	TPU, hardly inflammable, self-extinguishing
Contact material	CuZn
Contact surface material	Ni/Au
Contact carrier material	TPU GF
Material for screw connection	Zinc die-cast, nickel-plated

Connector

Connection 1

Type	Socket straight M12
Coding type	A

Connection 2

Type	Socket straight M12
Coding type	A

Connection 3

Type	Socket straight M12
Coding type	A

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 100
-----------------------------	------------

SAC-5P-M12YF/2XM12FS VP - Y distributor



1698013

<https://www.phoenixcontact.com/us/products/1698013>


Environmental and real-life conditions

Ambient conditions

Degree of protection	IP65
	IP67
	IP68
Ambient temperature (operation)	-25 °C ... 90 °C


Drawings

Schematic diagram

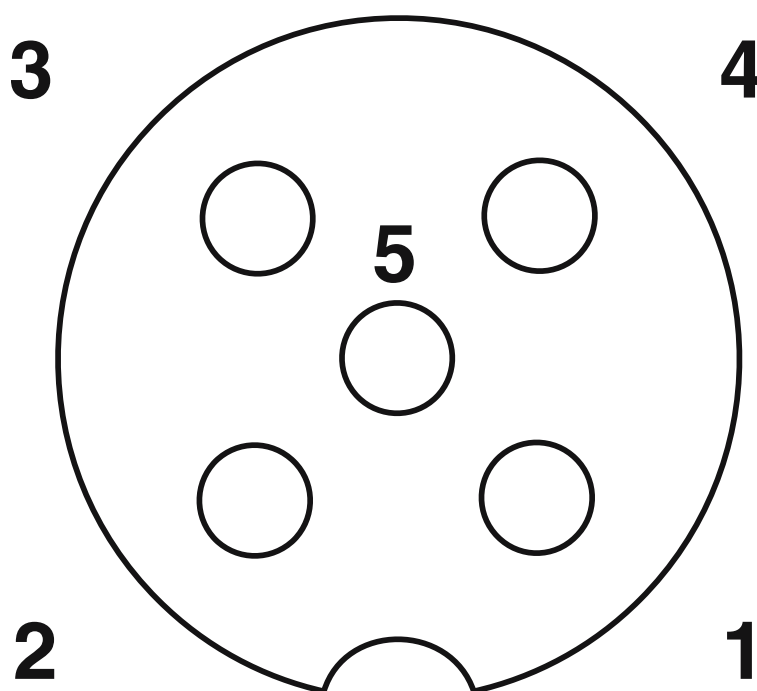

Pin assignment M12 socket, 5-pos., A-coded, socket side view

Schematic diagram

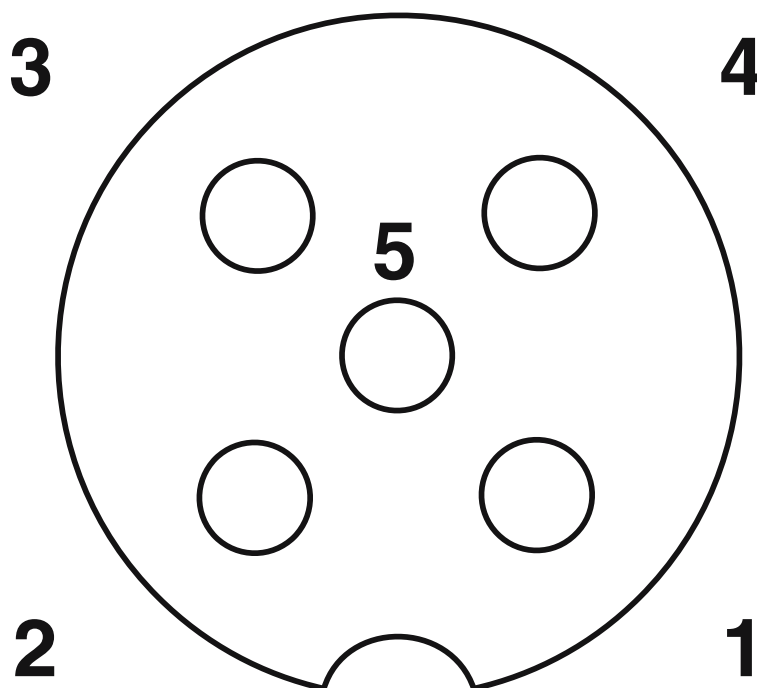

Pin assignment M12 socket, 5-pos., A-coded, socket side view

SAC-5P-M12YF/2XM12FS VP - Y distributor



1698013

<https://www.phoenixcontact.com/us/products/1698013>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1698013>

	 UL Listed Approval ID: E221474			
	Nominal voltage U _N	Nominal current I _N	Cross section AWG	Cross section mm ²
keine				
	30 V	4 A	-	-

	 cUL Listed Approval ID: E221474			
	Nominal voltage U _N	Nominal current I _N	Cross section AWG	Cross section mm ²
keine				
	30 V	4 A	-	-

SAC-5P-M12YF/2XM12FS VP - Y distributor



1698013

<https://www.phoenixcontact.com/us/products/1698013>

Classifications

ECLASS

ECLASS-13.0	27440106
ECLASS-15.0	27440106

ETIM

ETIM 9.0	EC002925
----------	----------

UNSPSC

UNSPSC 21.0	31251500
-------------	----------

SAC-5P-M12YF/2XM12FS VP - Y distributor



1698013

<https://www.phoenixcontact.com/us/products/1698013>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com