

# UM108 N-SE-A73 - Lateral element

2709383

<https://www.phoenixcontact.com/us/products/2709383>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Side element, without foot, low-profile version, for 73 mm wide U-shaped cover.



## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 2709383       |
| Packing unit                         | 10 pc         |
| Minimum order quantity               | 10 pc         |
| Sales key                            | AC13          |
| Product key                          | ACHDBB        |
| GTIN                                 | 4017918904098 |
| Weight per piece (including packing) | 11.36 g       |
| Weight per piece (excluding packing) | 11.2 g        |
| Customs tariff number                | 39269097      |
| Country of origin                    | PL            |

# UM108 N-SE-A73 - Lateral element

2709383

<https://www.phoenixcontact.com/us/products/2709383>



## Technical data

### Product properties

|                              |                               |
|------------------------------|-------------------------------|
| Product type                 | Panel mounting base side part |
| Housing type                 | Press-drawn section housings  |
| Housing series               | UM                            |
| Product family               | UM108                         |
| Ventilation openings present | no                            |

### Dimensions

|                     |        |
|---------------------|--------|
| Dimensional drawing |        |
| Depth               | 125 mm |

### Material specifications

|                                        |                  |
|----------------------------------------|------------------|
| Color (Housing)                        | green (RAL 6021) |
| Material                               | PA               |
| Flammability rating according to UL 94 | V0               |
| Surface characteristics                | untreated        |

### Environmental and real-life conditions

|                                 |                                                    |
|---------------------------------|----------------------------------------------------|
| Ambient conditions              |                                                    |
| Ambient temperature (operation) | -40 °C ... 105 °C (depending on power dissipation) |

# UM108 N-SE-A73 - Lateral element


2709383

<https://www.phoenixcontact.com/us/products/2709383>



## Drawings

Dimensional drawing

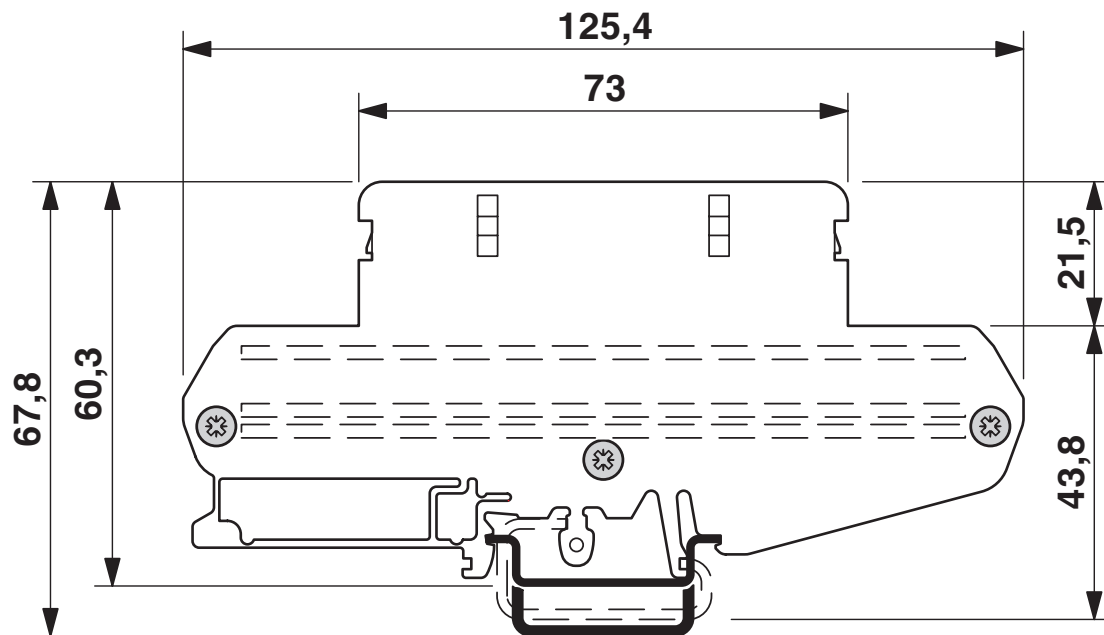

# UM108 N-SE-A73 - Lateral element

2709383

<https://www.phoenixcontact.com/us/products/2709383>



## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2709383>



**UL Recognized**

Approval ID: E240868

# UM108 N-SE-A73 - Lateral element



2709383

<https://www.phoenixcontact.com/us/products/2709383>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27190602 |
| ECLASS-15.0 | 27190602 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC002779 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# UM108 N-SE-A73 - Lateral element



2709383

<https://www.phoenixcontact.com/us/products/2709383>

## Environmental product compliance

|                                         |                                          |
|-----------------------------------------|------------------------------------------|
| EU RoHS                                 |                                          |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |                                          |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|                                         | No hazardous substances above the limits |
| EU REACH SVHC                           |                                          |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)