

# VS-SCRJ-PC-BK - Protective cover



1417840

<https://www.phoenixcontact.com/us/products/1417840>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Protective cover, degree of protection: IP67, material: Plastic, color: black



## Commercial data

Item number	1417840
Packing unit	100 pc
Minimum order quantity	100 pc
Product key	ABNNBZ
GTIN	4055626127217
Weight per piece (including packing)	3.551 g
Weight per piece (excluding packing)	3.551 g
Country of origin	CH

# VS-SCRJ-PC-BK - Protective cover

1417840

<https://www.phoenixcontact.com/us/products/1417840>

## Technical data


### Product properties

Product type	Protective cover
Type	SCRJ
Connection profile	SCRJ

### Electrical properties

Transmission medium	FO
---------------------	----

### Dimensions

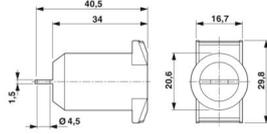Dimensional drawing	
Width	30 mm
Height	21 mm
Length	40.5 mm

### Material specifications

Color	black
Material	Plastic
Flammability rating according to UL 94	V0
Housing material	Plastic

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP67
Ambient temperature (operation)	-40 °C ... 80 °C


# VS-SCRJ-PC-BK - Protective cover

1417840

<https://www.phoenixcontact.com/us/products/1417840>

## Drawings

Dimensional drawing

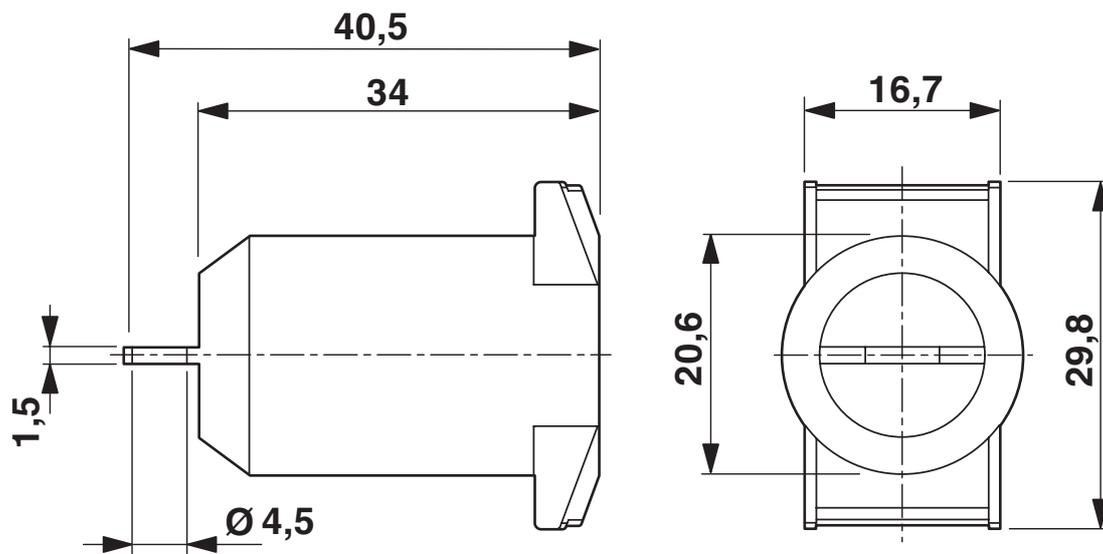

Protective cover, IP67

# VS-SCRJ-PC-BK - Protective cover



1417840

<https://www.phoenixcontact.com/us/products/1417840>

## Classifications

### ETIM

ETIM 8.0

EC002314

### UNSPSC

UNSPSC 21.0

39121400

# VS-SCRJ-PC-BK - Protective cover



1417840

<https://www.phoenixcontact.com/us/products/1417840>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)