

SACC-AT04-4P-IV - Connector housing

1520952

<https://www.phoenixcontact.com/us/products/1520952>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Connector housing, Crimp contacts



Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1520952 |
| Packing unit | 50 pc |
| Minimum order quantity | 50 pc |
| Sales key | BF72 |
| Product key | AF2IEA |
| GTIN | 4063151985417 |
| Weight per piece (including packing) | 22.22 g |
| Weight per piece (excluding packing) | 7 g |
| Country of origin | MX |

SACC-AT04-4P-IV - Connector housing

1520952

<https://www.phoenixcontact.com/us/products/1520952>



Technical data

Notes

| | |
|---------|-------------------------------|
| General | AT04-4P-BLK |
| General | Use with Size 16 pin contacts |

Product properties

| | |
|-------------------|----------------|
| Product type | Contact insert |
| Series | AT04 |
| Contact numbering | 1 - 4 |
| Shielded | no |

 
Electrical properties

| | |
|--------------------------------|--|
| Specific dielectric strength | 1500 V AC (Less than 2 mA current leakage) |
| Insulation resistance | 1000 MΩ (at 25 °C) |
| Nominal voltage U _N | 50 V AC/DC (IEC rating) |
| Nominal current I _N | 13 A (MAX) |

Connection data

| | |
|-------------------|----------------|
| Connection method | Crimp contacts |
|-------------------|----------------|

Dimensions

| | |
|---------------------|--|
| Dimensional drawing |  |
| Width | 21 mm |
| Height | 19.6 mm |
| Length | 46.2 mm |

Material specifications

| | |
|------------------------------|---------|
| Seal material Profile gasket | Silicon |
| Seal material Cable seal | Silicon |
| Housing material | PA-GF |

Mechanical properties

| | |
|-----------------------------|-------|
| Mechanical data | |
| Insertion/withdrawal cycles | ≥ 100 |

Characteristics

| | |
|------------------------------|--|
| Specific dielectric strength | 1500 V AC (Less than 2 mA current leakage) |
|------------------------------|--|

Environmental and real-life conditions

SACC-AT04-4P-IV - Connector housing

1520952

<https://www.phoenixcontact.com/us/products/1520952>



Ambient conditions

| | |
|---------------------------------|---|
| Degree of protection | IP68 (in mated condition) IP69K (in mated condition) |
| Ambient temperature (operation) | -55 °C ... 125 °C |

SACC-AT04-4P-IV - Connector housing




1520952

<https://www.phoenixcontact.com/us/products/1520952>


Drawings

Dimensional drawing

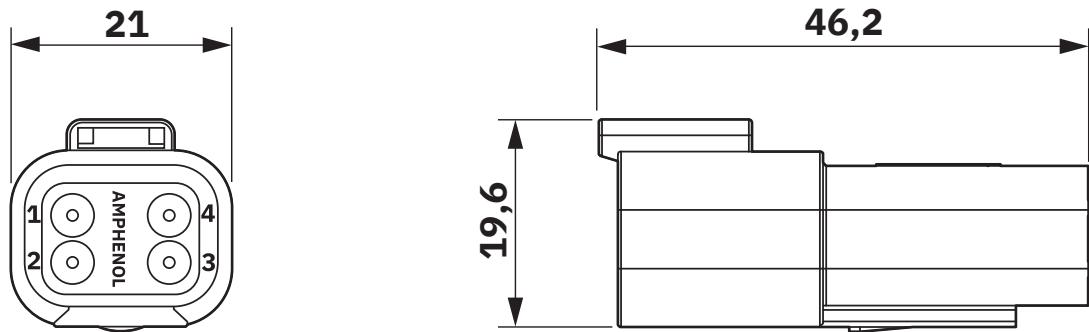

AT04-4P top view and side view

Schematic diagram

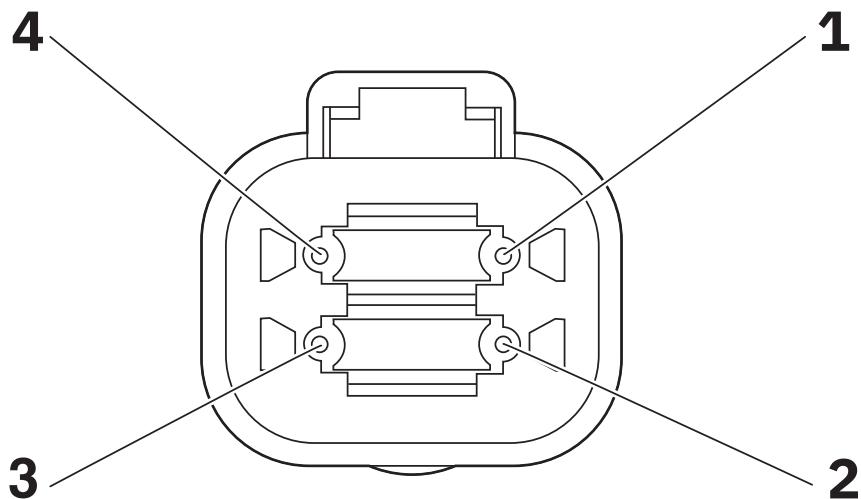

AT04-4P pin assignment

SACC-AT04-4P-IV - Connector housing

1520952

<https://www.phoenixcontact.com/us/products/1520952>



Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-15.0 | 27440116 |
| ECLASS-13.0 | 27440116 |

ETIM

| | |
|----------|----------|
| ETIM 9.0 | EC002635 |
|----------|----------|

SACC-AT04-4P-IV - Connector housing

1520952

<https://www.phoenixcontact.com/us/products/1520952>



Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com