

# CK2,5-ED-2,50ST-S AG - Crimp contact

1663873

<https://www.phoenixcontact.com/us/products/1663873>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Crimp contact, series: HC-HV, Pin, turned, contact diameter: 2.5 mm, connection cross section: 2.5 mm<sup>2</sup> ... 2.5 mm<sup>2</sup>, AWG 14...14, contact material: Cu alloy

## Commercial data

Item number	1663873
Packing unit	100 pc
Minimum order quantity	100 pc
Sales key	BF65
Product key	AF7AID
GTIN	4017918123543
Weight per piece (including packing)	1.23 g
Weight per piece (excluding packing)	1.23 g
Customs tariff number	85366990
Country of origin	DE

# CK2,5-ED-2,50ST-S AG - Crimp contact



1663873

<https://www.phoenixcontact.com/us/products/1663873>

## Technical data

### Notes

General	For HC-HV contact carriers, the quality of a crimp connection is determined by DIN EN 60 352-2
---------	--

### Product properties

Product type	Crimp contact
Series	HC-HV
Contact material type	turned
Special properties	last make, first break

### Connection data

 
Connection technology	
Contact connection type	Pin
Connection method	Crimp connection

Conductor connection	
Stripping length	7.5 mm
Connection cross section	2.5 mm <sup>2</sup> ... 2.5 mm <sup>2</sup>
Connection cross section AWG	14 ... 14

### Material specifications

Material Contact	Cu alloy
Material Contact surface	Ag

### Dimensions

Dimensional drawing	
Diameter (Contact diameter)	2.5 mm

### Mechanical properties

Mechanical data	
Insertion/withdrawal cycles	≥ 500

### Environmental and real-life conditions

Ambient conditions	
Ambient temperature (operation)	-40 °C ... 125 °C

# CK2,5-ED-2,50ST-S AG - Crimp contact


1663873

<https://www.phoenixcontact.com/us/products/1663873>



## Drawings

Dimensional drawing

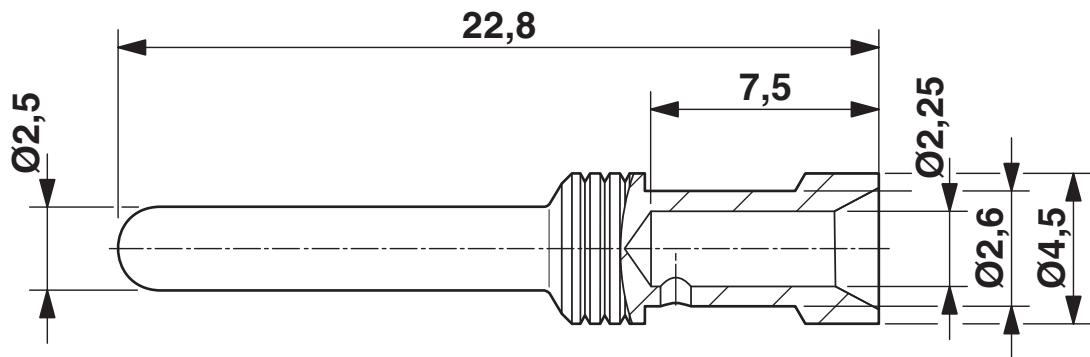

Dimensional drawing

# CK2,5-ED-2,50ST-S AG - Crimp contact

1663873

<https://www.phoenixcontact.com/us/products/1663873>



## Approvals

ⓘ To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1663873>



**EAC**

Approval ID: RU C-DE.AI30.B.01102

# CK2,5-ED-2,50ST-S AG - Crimp contact

1663873

<https://www.phoenixcontact.com/us/products/1663873>



## Classifications

### ECLASS

ECLASS-13.0	27440204
ECLASS-15.0	27440204

### ETIM

ETIM 9.0	EC000796
----------	----------

### UNSPSC

UNSPSC 21.0	39121500
-------------	----------

# CK2,5-ED-2,50ST-S AG - Crimp contact

1663873

<https://www.phoenixcontact.com/us/products/1663873>



## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.	

### EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	7fa0657f-ed4a-439d-b89c-fa221db6ac1a

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

### Phoenix Contact USA

586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)