

# UM-PRO A/U N 73 CM - Covering hood

2200310

<https://www.phoenixcontact.com/us/products/2200310>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Press-drawn section housings, Latching, Cover, width: 73 mm, profile length (configurable): 3 cm ... 100 cm, height: 24 mm, Note: max. length of the cover = PCB length - 19 mm



## Your advantages

- Tailor-made housing length, can be cut to length with millimeter precision
- Easy integration of large electronics components, thanks to the open design
- Heat-resistant UM-PRO made from polyamide with UL approval up to 100°C
- Easy device mounting thanks to snap-mount principle (the sides are fixed without the aid of tools)
- High degree of flexibility, thanks to freely positionable covering hoods

## Commercial data

Item number	2200310
Packing unit	1 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Sales key	AC17
Product key	ACHDAZ
Customs tariff number	39162000
Country of origin	DE

# UM-PRO A/U N 73 CM - Covering hood



2200310

<https://www.phoenixcontact.com/us/products/2200310>

## Technical data

### Notes

Assembly note	Please observe the application note in the download area.
---------------	---

### Product properties

Product type	Component housing cover
Housing type	Press-drawn section housings
Housing series	UM-PRO
Ventilation openings present	no

### Dimensions

Dimensional drawing	
Width	73 mm
Height	24 mm

### Material specifications

Color (Housing)	transparent
Material	PC
Flammability rating according to UL 94	V0
Surface characteristics	untreated

### Environmental and real-life conditions

Ambient conditions	
Ambient temperature (operation)	-40 °C ... 105 °C (depending on power dissipation)
Ambient temperature (storage/transport)	-40 °C ... 70 °C
Ambient temperature (assembly)	-5 °C ... 100 °C
Relative humidity (storage/transport)	95 %

### Mounting

Mounting type	Latching
Mounting position	vertical or horizontal

### Packaging specifications

Type of packaging	packed in cardboard
Outer packaging type	Carton

# UM-PRO A/U N 73 CM - Covering hood




2200310

<https://www.phoenixcontact.com/us/products/2200310>

## Drawings

Dimensional drawing

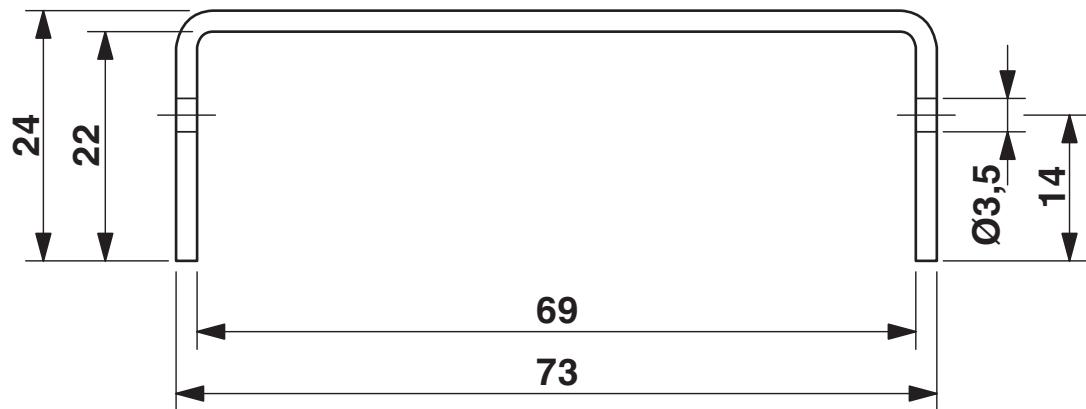

# UM-PRO A/U N 73 CM - Covering hood

2200310

<https://www.phoenixcontact.com/us/products/2200310>



## Approvals

ⓘ To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2200310>



**UL Recognized**

Approval ID: E240868

# UM-PRO A/U N 73 CM - Covering hood

2200310

<https://www.phoenixcontact.com/us/products/2200310>



## Classifications

### ECLASS

ECLASS-13.0	27190603
ECLASS-15.0	27190603

### ETIM

ETIM 9.0	EC002779
----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

# UM-PRO A/U N 73 CM - Covering hood

2200310

<https://www.phoenixcontact.com/us/products/2200310>



## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)