

# UM 72-SEPEF/L - Lateral element



2906487

<https://www.phoenixcontact.com/us/products/2906487>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Side element, left, with foot, width: 5 mm, length: 72 mm, for mounting on NS 32 or NS 35/7.5, with PE contact to the DIN rail



## Your advantages

- Easy installation
- Flexible size and shape
- Inexpensive as a result of reducing the number of separate housing parts

## Commercial data

Item number	2906487
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	AC13
Product key	ACHDBA
GTIN	4017918131319
Weight per piece (including packing)	12.04 g
Weight per piece (excluding packing)	11.9 g
Customs tariff number	39269097
Country of origin	PL

# UM 72-SEPEF/L - Lateral element

2906487

<https://www.phoenixcontact.com/us/products/2906487>



## Technical data

### Product properties

Product type	Panel mounting base side part
Housing type	Press-drawn section housings
Housing series	UM
Product family	UM72

### Dimensions

Depth	89.6 mm
-------	---------

### Material specifications

Color (Housing)	green (RAL 6021)
Material	PA
Flammability rating according to UL 94	V0
Surface characteristics	untreated

### Environmental and real-life conditions

Ambient conditions	
Ambient temperature (operation)	-40 °C ... 105 °C (depending on power dissipation)

### PCB data

Number of PCB holders	2
-----------------------	---

# UM 72-SEPEF/L - Lateral element


2906487

<https://www.phoenixcontact.com/us/products/2906487>



## Drawings

Drilling plan/solder pad geometry

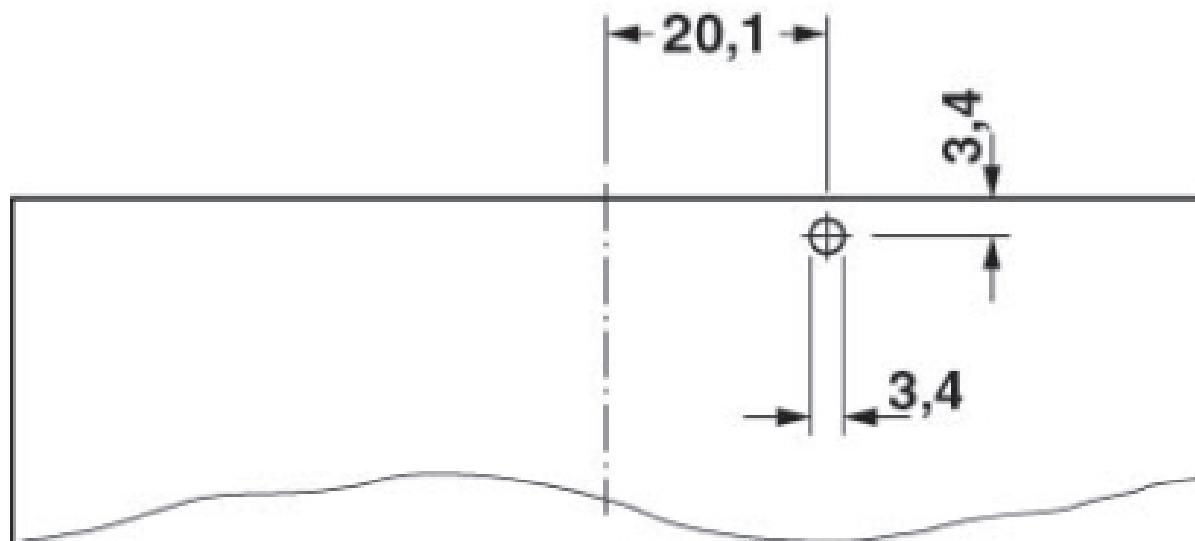

# UM 72-SEPEF/L - Lateral element

2906487

<https://www.phoenixcontact.com/us/products/2906487>



## Approvals

ⓘ To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2906487>



**UL Recognized**  
Approval ID: E240868

# UM 72-SEPEF/L - Lateral element

2906487

<https://www.phoenixcontact.com/us/products/2906487>



## Classifications

### ECLASS

ECLASS-13.0	27190602
ECLASS-15.0	27190602

### ETIM

ETIM 9.0	EC002779
----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

# UM 72-SEPEF/L - Lateral element

2906487

<https://www.phoenixcontact.com/us/products/2906487>



## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)