

UM122-PROFIL 100CM - Profile

2914576

<https://www.phoenixcontact.com/us/products/2914576>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Press-drawn section housings, Latching with side elements, latching with foot element, Basic profile, profile width (internal): 122 mm, profile width (external): 127.5 mm, length: 1000 mm, Note: required profile length = PCB length - 9.5 mm



Commercial data

Item number	2914576
Packing unit	1 m
Minimum order quantity	1 m
Sales key	AC13
Product key	ACHDBA
GTIN	4017918959166
Weight per piece (including packing)	300 g
Weight per piece (excluding packing)	509 g
Customs tariff number	39162000
Country of origin	DE

UM122-PROFIL 100CM - Profile



2914576

<https://www.phoenixcontact.com/us/products/2914576>


Technical data

Product properties

Product type	Component housing lower part
Housing type	Press-drawn section housings
Housing series	UM
Product family	UM122
Ventilation openings present	no

Dimensions

Dimensional drawing	
Length	1 m

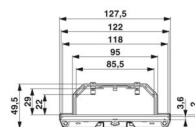

External dimensions

Profile width (external)	127.5 mm
--------------------------	----------

Internal dimensions

Profile width (internal)	122 mm
--------------------------	--------

Material specifications

Color (Housing)	green (RAL 6021)
Material	PVC
Flammability rating according to UL 94	V0

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-15 °C ... 50 °C
---------------------------------	------------------

PCB data

Number of PCB holders	1
-----------------------	---

Mounting

Mounting type	Latching with side elements, latching with foot element
---------------	---

UM122-PROFIL 100CM - Profile


2914576

<https://www.phoenixcontact.com/us/products/2914576>




Drawings

Dimensional drawing

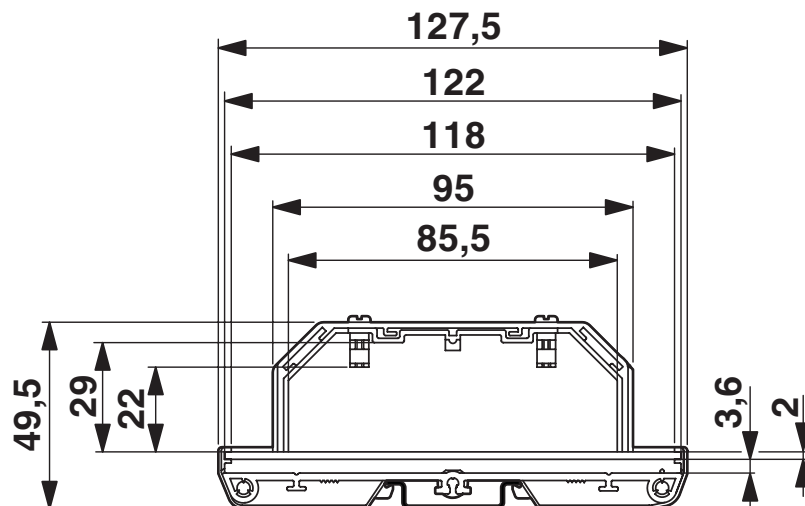

Dimensional drawing

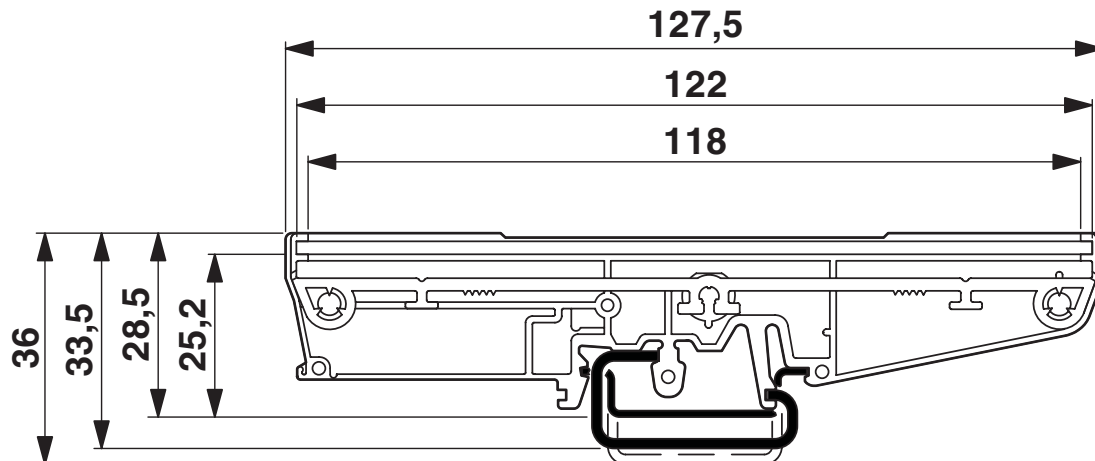

UM122-PROFIL 100CM - Profile



2914576

<https://www.phoenixcontact.com/us/products/2914576>

Classifications

ECLASS

ECLASS-13.0	27190601
ECLASS-15.0	27190601

ETIM

ETIM 9.0	EC002779
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

UM122-PROFIL 100CM - Profile

2914576

<https://www.phoenixcontact.com/us/products/2914576>



Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com