


EB 10-12 - Insertion bridge



3006137

<https://www.phoenixcontact.com/us/products/3006137>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

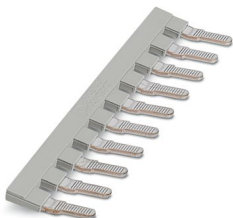

Insertion bridge, pitch: 12 mm, number of positions: 10, color: gray

Commercial data

Item number	3006137
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BE19
Product key	BE1Z2X
GTIN	4017918091361
Weight per piece (including packing)	20.18 g
Weight per piece (excluding packing)	20.18 g
Customs tariff number	85366990
Country of origin	PL

EB 10-12 - Insertion bridge

3006137

<https://www.phoenixcontact.com/us/products/3006137>



Technical data

Product properties

Product type	Insertion bridge
Number of positions	10
Pitch	12 mm
Potentials	10

Dimensions

Pitch	12 mm
-------	-------

Material specifications

Color	gray (RAL 7042)
Material	Copper
Flammability rating according to UL 94	V2
Insulating material	PA

Mounting

Mounting type	Screw mounting
---------------	----------------

EB 10-12 - Insertion bridge



3006137

<https://www.phoenixcontact.com/us/products/3006137>

Classifications

ECLASS

ECLASS-13.0	27250303
ECLASS-15.0	27250303

ETIM

ETIM 9.0	EC000489
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

EB 10-12 - Insertion bridge

3006137

<https://www.phoenixcontact.com/us/products/3006137>



Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%
EF3.0 Climate Change	
CO2e kg	0.286 kg CO2e

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com