

C-SCFMI 1,5/6,3X0,8 - Connector



3240529

<https://www.phoenixcontact.com/us/products/3240529>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Flat plug distributor, isolated, red, 0.5 - 1.5 mm², for plug and sleeve 6.3 x 0.8 mm

Your advantages

- Hard-soldered crimping zone for maximum conductor pull-out forces in connection with CRIMPFOX RCI... pliers
- Easy and reliable conductor entry thanks to 'EASY ENTRY'
- Halogen-free
- Electrogalvanized

Commercial data

Item number	3240529
Packing unit	50 pc
Minimum order quantity	50 pc
Sales key	BH34
Product key	BH3451
GTIN	4046356527996
Weight per piece (including packing)	1.403 g
Weight per piece (excluding packing)	1.403 g
Customs tariff number	85366990
Country of origin	CN

C-SCFMI 1,5/6,3X0,8 - Connector

3240529

<https://www.phoenixcontact.com/us/products/3240529>




Technical data

Product properties

Product type	Connector
Product property	Halogen-free
	With "Easy Entry" (conical insertion area)
	Brazed
	PA-insulated
	Tin-plated
	Temperature range: -20°C ... +105°C
	Flammability rating V2 in accordance with UL 94

Dimensions

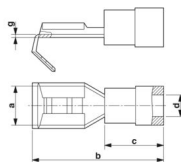Dimensional drawing	
Width	6.3 mm
Sleeve length	22.5 mm
Length of the insulating material sleeve	10.5 mm
Maximum stripping length	7 mm
Min. material thickness	0.4 mm
Inner dimensions of the insulating collar	41 mm

Material specifications

Color	red (RAL 3001)
Material	Brass
Flammability rating according to UL 94	V2
Coating	electrogalvanized
Insulating material	PA
Components	halogen-free

Mechanical properties

Technical data

Sleeve length	22.5 mm
---------------	---------

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-20 °C ... 105 °C
Permanent temperature	105 °C
Short-term temperature	120 °C

C-SCFMI 1,5/6,3X0,8 - Connector


3240529

<https://www.phoenixcontact.com/us/products/3240529>



Drawings

Dimensional drawing

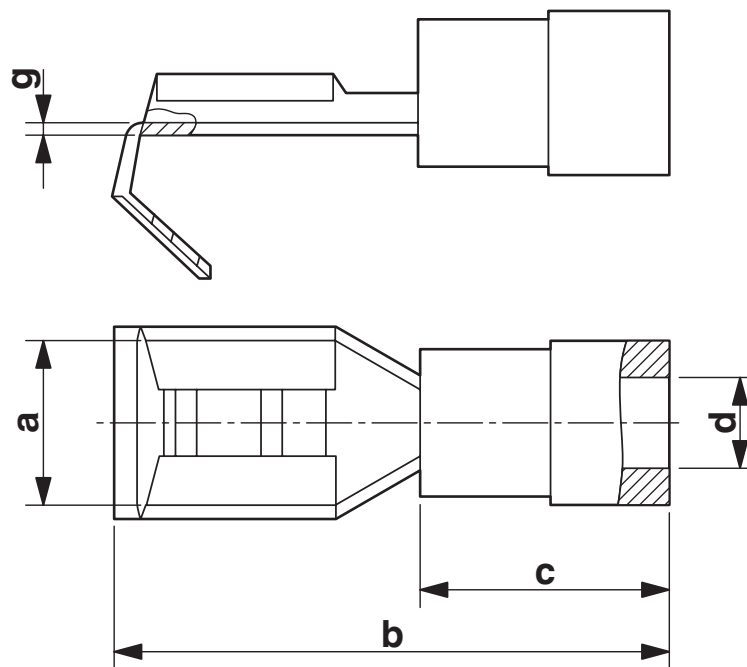

C-SCFMI 1,5/6,3X0,8 - Connector

3240529

<https://www.phoenixcontact.com/us/products/3240529>



Classifications

ECLASS

ECLASS-13.0	27400204
ECLASS-15.0	27400204

ETIM

ETIM 9.0	EC001052
----------	----------

UNSPSC

UNSPSC 21.0	27121700
-------------	----------

C-SCFMI 1,5/6,3X0,8 - Connector



3240529

<https://www.phoenixcontact.com/us/products/3240529>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com