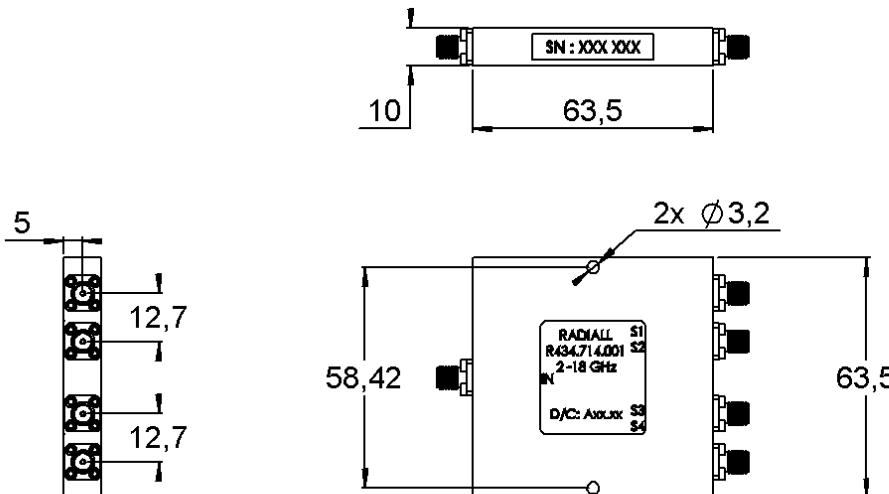
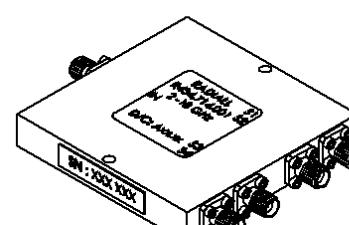


PAGE 1/2	ISSUE 15-06-07A	SERIES SPLITTER	PART NUMBER <b>R434714001</b>
			
			
<p>All dimensions are in mm.</p> <p>Weight <b>112,0000</b> g</p> <p>Specification</p> 			

PAGE 2/2

ISSUE 15-06-07A

SERIES  
SPLITTER

PART NUMBER R434714001

## ELECTRICAL CHARACTERISTICS

Frequency range :	2 - 18 GHz
Number of ways	4
Phase	0°
VSWR	
Input	1.7
Output	1.7
Impedance	50 Ohms
Insertion loss	1.8 dB max
Isolation	17 dB mini
Amplitude balance	± 0.5 dB
Phase Balance	± 12°
Average Power	
VSWR load < 1.2	30W
VSWR load : inf	1W

## MECHANICAL CHARACTERISTICS

Connectors :	
Input	SMA female
Output	SMA female
Body	Aluminium
Finish	Blue Paint

## ENVIRONMENTAL CHARACTERISTICS

Operating temperature	-40 / +85 °C
Storage temperature	-55 / +125 °C