


## Universal Thin Client Monitor Mount

MODEL NUMBER: DMATC

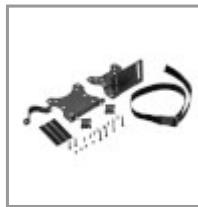

Thin client mounting bracket secures your small desktop terminal to your monitor, freeing up desk, table and floor space.

### Features

**Ideal for Use at Home, School and the Office** This thin client mount securely attaches to the back of your monitor, hiding your thin client out of the way and saving valuable desk, table and floor space. The adjustable frame fits most thin clients ranging from 0.76 to 2.8 inches wide and supports up to 11 pounds (4.9 kg).

**Convenient Open Frame Design Allows Easy Access** The open frame allows you access to your thin client and its cabling for easy adjustments. Made from durable steel, the thin client mounting bracket features a scratch-resistant black powder-coated finish that blends with your décor and stands up to frequent handling.

**Versatile Mounting Options Give You More Choices** In addition to easy mounting to your monitor's 75 x 75 mm or 100 x 100 mm VESA plate, the thin client mount also attaches directly to a display mount pole, under a desk or on a wall. Mounting hardware and hook-and-loop straps for extra stability are included.

**5-Year Warranty and Environmentally Responsible Design** The DMATC comes with a 5-year warranty. It's manufactured in compliance with strict RoHS specifications.

## Specifications

OVERVIEW	
UPC Code	037332212771
Device Compatibility	Monitor/HDTV
Accessory Type	Displaymount Adapter Kit
Accessory Class	Display Mount Accessories
PHYSICAL	
Color	Black

### Highlights

- Mounts to back of your monitor to leave valuable desk, table and floor space clear
- Adjusts to fit wide range of thin clients from 0.76 to 2.8 in. and up to 11 lbs (4.9 kgs)
- Scratch-resistant powder-coated finish blends into your workspace décor
- Included hardware for pole, desk, wall or VESA mounting gives you installation choices
- Open frame design allows easy access to thin client and cabling for quick adjustments

### Applications

- Incorporate a thin client into your workspace without taking up valuable desk, table or floor space

### Package Includes

- Thin client bracket
- Safety strap
- Support bracket
- (3) Rubber strips
- (4) ST4.8 x 16 screws
- (2) M5 x 25 screws
- (8) M4 x 12 screws
- (4) D4 washers
- (4) M4 nuts
- Owner's manual



Powering Business Worldwide

TRIPP LITE  
SERIES

Material of Construction	Steel
VESA Pattern (mm)	75x75; 100x100
Motion	Fixed
Mounting Location	Wall
Degrees of Motion	Fixed
Maximum Weight Capacity (lbs.)	11
Maximum Weight Capacity (kg)	5
Number of Displays	1
Unit Dimensions (hwd / in.)	4.600 x 5.100 x 2.800
Unit Dimensions (hwd / cm)	11.7 x 12.9 x 7.1
Unit Weight (lbs.)	1.5
Unit Weight (kg)	0.68
Assembly Required	Yes
<b>FEATURES &amp; SPECIFICATIONS</b>	
Antimicrobial	No
Cord Management	No
IP68 Rated	No
IP20 Rated	No
Tools Necessary	Yes
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS; RoHS3; CE (Europe); REACH
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2026 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.