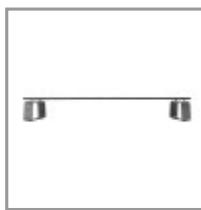


Universal Glass-Top Monitor Riser

MODEL NUMBER: **MR2208G**

Raises your monitor 3 in. above your desk, table or workspace's surface to help ease eye and neck strain and free up valuable space. Also ideal for laptops, printers, fax machines and small televisions.

Description

The MR2208G Universal Glass-Top Monitor Riser not only frees up valuable space on your desk, table or workstation, it does so with chic, contemporary style and modern smoke glass, that fits perfectly into any home or office décor. By placing your monitor three inches above the surface, the MR2208G also helps ease eye and neck strain. The extra-large 8 x 22-inch tempered glass platform supports up to 40 lbs (18.1 kgs), making it also ideal for laptops, printers, fax machines and small televisions. Brushed aluminum legs with rubber feet secure the riser on smooth surfaces. A keyboard can fit easily beneath the glass platform for convenient storage. The MR2208G assembles in seconds using the included hardware.

Features

Raises a Monitor 3 in. Above Your Desk's SurfaceFree up valuable work spaceHelps ease strain on eyes and neckFor home or officeAllows room underneath for keyboard storageAlso ideal for laptops, printers, fax machines and small televisions

Durable ConstructionExtra-large 8 x 22 in. tempered smoke glass platform supports up to 40 lb. Brushed aluminum legs with rubber feet secure riser on smooth surfacesAssembles easily in seconds using included hardwareContemporary easy-cleaning design fits any home or office décor

Specifications

OVERVIEW	
UPC Code	037332197306
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Silver
Material of Construction	Glass (Top), Metal (Legs)
Mounting Location	Desktop

Highlights

- Extra-large 8 x 22 in. tempered smoke colored glass platform
- Brushed aluminum legs with rubber feet
- Allows room underneath for keyboard storage
- Supports up to 40 lbs (18.1 kgs)
- Assembles easily in seconds

Package Includes

- Glass platform
- (2) Legs
- (4) M6 x 6 silver hex key screws
- Hex key, 4 mm
- Installation guide



Powering Business Worldwide

TRIPP LITE
SERIES

Maximum Weight Capacity (lbs.)	40
Maximum Weight Capacity (kg)	18
Number of Displays	1
Shipping Dimensions (hwd / in.)	1.90 x 24.30 x 8.70
Shipping Dimensions (hwd / cm)	4.83 x 61.72 x 22.10
Shipping Weight (lbs.)	5.08
Shipping Weight (kg)	2.30
Unit Dimensions (hwd / in.)	3.150 x 22.020 x 8.270
Unit Weight (lbs.)	3.90
Unit Weight (kg)	1.77
Assembly Required	Yes
FEATURES & SPECIFICATIONS	
Antimicrobial	No
Cord Management	No
Tools Necessary	No
Security Lock	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; RoHS3; CE (Europe); REACH
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2026 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.