


SmartRack 1U Hinged Wall-Mount Patch Panel Bracket

MODEL NUMBER: **N060-001**

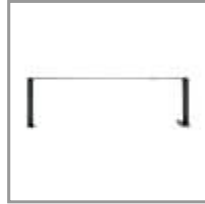

Highlights

- Precision-made from heavy-duty 14ga steel with black finish
- Supports universal left- or right-hinge mounting
- Keyhole mounting slots spaced 16 in. apart to align with wall studs
- Rear cutout for through-the-wall cabling
- Compatible with standard 19 in. patch panels

Package Includes

- N060-001 1U Hinged Wall-Mount Patch Panel Bracket
- (4) Mounting screws

Mounts a patch panel or network switch to a wall, while providing easy access to rear cabling. A dependable alternative to full-size rack installation recommended for server rooms.

Description

The N060-001 1U Hinged Wall-Mount Patch Panel Bracket allows you to mount a 1U patch panel or network switch to a wall instead of investing in a full-size rack. Precision-made from heavy-duty 14-gauge steel with a glossy black finish, this bracket supports universal left- or right-hinge mounting that accepts standard 19-inch patch panels. Two keyhole slots are spaced 16 inches apart to align with wall studs to ensure secure wall-mounting. The rear cutout lets you feed cable through a wall opening to streamline installations and reduce cable clutter. Smooth laser-cut edges protect cable jackets from damage and wear. Stamped horizontal reinforcement ribs on the back of the bracket keep mounted equipment stable and secure.

Features

Dependable Alternative to Expensive Rack-Mounting

- Mounts a 1U patch panel or network switch to a wall
- Supports universal left- or right-hinge mounting
- Compatible with standard 19 in. patch panels

Built for Stability

- Keyhole mounting slots spaced 16 in. apart to align with wall studs
- Stamped horizontal reinforcement ribs on rear keep mounted equipment secure

Convenient Rear Cutout

- Allows cable to be fed through wall openings
- Streamlines installations and reduces cable clutter

Precision-Made with Laser-Cut Metal

- Heavy-duty 14ga steel construction with glossy black finish
- Smooth laser-cut edges protect cables from damage and wear



Powering Business Worldwide

TRIPP LITE
SERIES

Specifications

OVERVIEW	
UPC Code	037332197887
Accessory Type	Mounting Bracket
Technology	Cat5/5e; Cat6; Cat6a
Accessory Class	Rack Accessories
PHYSICAL	
Color	Black
Rack Height	1U
Maximum Device Depth (cm)	13.97
Maximum Device Depth (in.)	5.5
Maximum Device Depth (mm)	140
Shipping Dimensions (hwd / in.)	2.40 x 6.40 x 21.10
Shipping Dimensions (hwd / cm)	6.10 x 16.26 x 53.59
Shipping Weight (lbs.)	1.60
Shipping Weight (kg)	0.73
Unit Dimensions (hwd / in.)	5.827 x 19.370 x 1.252
Unit Dimensions (hwd / cm)	14.8 x 49.2 x 3.18
Unit Weight (lbs.)	1.25
Unit Weight (kg)	0.57
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2026 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.