


## 12-Port Wall-Mount Patch Panel for UTP Keystone Jacks, Offset Ports, TAA

MODEL NUMBER: **N062-012-KJ-WOF**

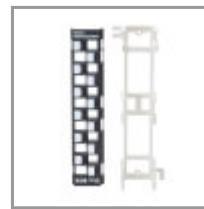

Manages and organizes input/output network cable connections in your small network closet, including audio/video, VoIP, Ethernet and USB.

### Highlights

- 12 blank cutouts accommodate all UTP keystone jacks, including RJ45, HDMI and USB
- Installs on a wall vertically or horizontally with included mounting bracket
- Ports are numbered and labeled for at-a-glance connection identification
- Recommended for AV, VoIP, Ethernet and other applications in small network closets
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

### Package Includes

- N062-012-KJ-WOF 12-Port Wall-Mount Patch Panel
- Mounting bracket
- Installation instructions

### Features

#### Manages and Organizes up to 12 Cable Connections

This 12-port patch panel is ideal for wall mounting in small network closets or near a desk or workspace. Twelve blank offset cutouts accommodate almost any standard keystone jack, including RJ45 Ethernet, HDMI and USB. Ports are numbered and labeled to help you identify individual cable runs at a glance.

#### Designed for Easy Custom Installation

The 12-port patch panel mounts to a wall, desk or similar flat surface in either horizontal or vertical mode, so you can easily organize inputs to your specific requirements. It easily snaps into and out of the frame, allowing you to remove it to make new connections and snap it back into place.

#### TAA-Compliant for GSA Schedule Purchases

The N062-012-KJ-WOF is compliant with the Federal Trade Agreements Act (TAA), which makes it eligible for GSA (General Services Administration) Schedule and other federal procurement contracts.

## Specifications

OVERVIEW	
UPC Code	037332285140
Product Type	Wall Mount
Technology	Cat5/5e; Cat6; Cat6a
CONNECTIONS	
Number of Ports	12
Ports Detail	12 DEDICATED PORTS AVAILABLE FOR MOUNTING STANDARD KEYSTONE JACKS
Side A - Connector 1	KEYSTONE JACK CUTOUT



Powering Business Worldwide

TRIPP LITE  
SERIES

Side B - Connector 1	KEYSTONE JACK CUTOUT
<b>PHYSICAL</b>	
Color	Black
Material of Construction	PANEL: SECC; WM BRACKET: ABS (UL94V-0)
Mounting Holes or Slots	Yes
Total Number of Ports	12
Rackmountable	No
Shipping Dimensions (hwd / in.)	3.03 x 11.18 x 3.11
Shipping Weight (lbs.)	0.66
Shipping Weight (kg)	0.30
Unit Dimensions (hwd / in.)	9.960 x 2.550 x 2.750
Housing	SECC
Mounting Details	WALL MOUNT
Panel Style	Blank
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	14° to 140°F (-10° to 60°C)
Storage Temperature Range	-40° to 158°F (-40° to 70°C)
Operating Humidity Range	10% TO 90% RH, NON-CONDENSING
Storage Humidity Range	10% TO 90% RH, NON-CONDENSING
<b>FEATURES &amp; SPECIFICATIONS</b>	
Mounting Accessory Included	Yes
Breakout	No
Numbered Ports	Yes
Driver Required	No
DIN Mountable	No
Keystone Jacks	Yes
Labeled Ports	No
Panel Applications	Audio/Video; Ethernet; USB
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Certifications	UL 94
Product Compliance	REACH; RoHS; Trade Agreements Act (TAA)
<b>WARRANTY &amp; SUPPORT</b>	



*Powering Business Worldwide*

TRIPP LITE  
SERIES

Product Warranty Period (Worldwide)	Lifetime limited warranty
-------------------------------------	---------------------------

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2026 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.