
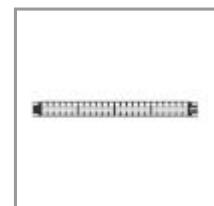


48-Port 1U Rack-Mount Unshielded Blank Keystone/Multimedia Patch Panel, RJ45 Ethernet, USB, HDMI, Cat5e/6

MODEL NUMBER: **N062-048-KJ**

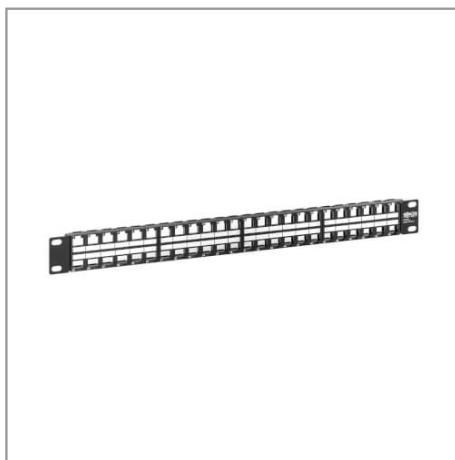

Manages and organizes network cables in a variety of applications, including audio/video, voice, Ethernet and USB.

Highlights

- 48 blank cutouts compatible with keystone jacks, including AV Connectors and N235 Series RJ45 jacks
- Ideal for Ethernet, voice, audio/video and USB applications for home or office
- Numbered ports allow easy identification of jacks and cabling
- Heavy-duty cold-rolled steel construction designed for long life
- Mounts easily into 1U of space in an EIA-standard 19 in. 2-post rack

Package Includes

- N062-048-KJ 48-Port 1U Rack-Mount Unshielded Blank Keystone/Multimedia Patch Panel
- (x25) Cable Ties
- Quick Start Guide

Features

Manages and Organizes up to 48 Network Connections

This 1U unshielded patch panel features 48 blank cutouts that accommodate any type of keystone jack, including RJ45 Ethernet, HDMI audio/video, voice and USB. Each port is clearly numbered to help you identify connections.

Quick and Easy to Install in Your Rack

Made from long-lasting cold-rolled steel, the N062-048-KJ patch panel mounts easily in 1U of an EIA-standard 19-inch 2-post rack.

Specifications

OVERVIEW	
UPC Code	037332276858
Product Type	Rackmount
Technology	Cat5/5e; Cat6; Cat6a; DisplayPort; HDMI; USB 2.0 (High Speed)
Firmware / Software Docs	
Offset Ports	No
CONNECTIONS	
Number of Ports	48
Side A - Connector 1	KEYSTONE JACK CUTOUT



Powering Business Worldwide

TRIPP LITE
SERIES

Side B - Connector 1	KEYSTONE JACK CUTOUT
PHYSICAL	
Color	Black
Material of Construction	Rear Panel: SPCC; Frame: ABS + PC
Rack Height	1U
Shipping Dimensions (hwd / in.)	2.80 x 4.00 x 22.10
Shipping Weight (lbs.)	1.20
Unit Dimensions (hwd / in.)	1.740 x 19.000 x 0.500
Panel Style	Blank
ENVIRONMENTAL	
Operating Temperature Range	14° to 140°F (-10° to 60°C)
Storage Temperature Range	-40° to 158°F (-40° to 70°C)
Operating Humidity Range	10% to 90% RH, Non-Condensing
Storage Humidity Range	10% to 90% RH, Non-Condensing
FEATURES & SPECIFICATIONS	
Numbered Ports	Yes
EIA/TIA 2/32 Spacing	No
Down-Angled Ports	No
Panel Applications	Audio/Video; Ethernet; USB; Voice
STANDARDS & COMPLIANCE	
Product Compliance	CE (Europe); REACH; RoHS; UKCA
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.