


48-Port Cat6 Patch Panel - UTP, 110 Punch Down, RJ45, 2U, TAA

MODEL NUMBER: N252-048

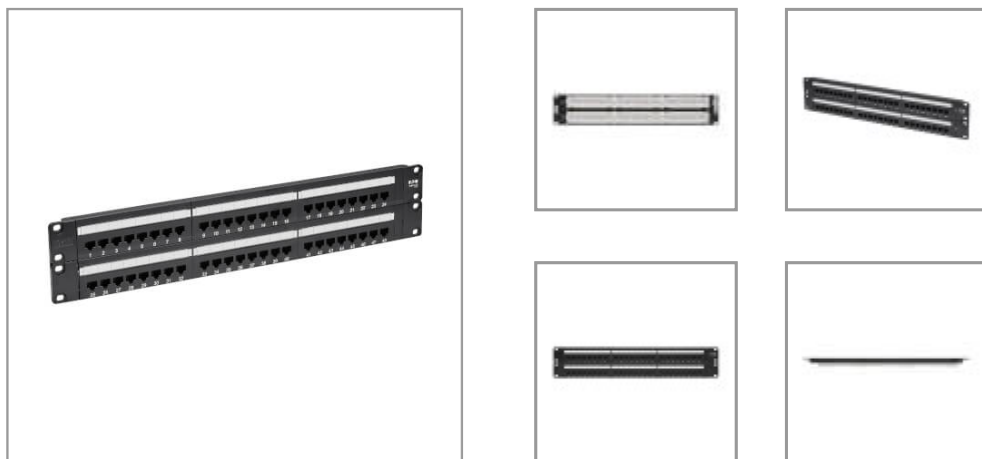

Manages and organizes Cat6 input/output cable connections in your high-density Gigabit Ethernet network.

Features

48-Port Patch Panel for High-Speed Cat6 Network Cabling

Organize and manage your high-density Cat6 application without taking up too much valuable rack space. This patch panel offers 48 RJ45 ports with color-coded 110 punch-down slots that are terminated using a proper punch-down tool. Both the front and rear connectors are clearly numbered and labeled (for custom naming) to help you identify individual cable runs. The patch panel supports T568A and T568B wiring standards.

Condenses 48 Ports into Just 2U of Space in Your 19 in. Enclosure or Open Frame Rack

The UL-approved patch panel supports mounting in 2U of EIA-standard 19-inch racks using the included hardware, freeing up valuable rack space for other equipment. It is fully rated for 1 Gbps data transfer speeds to connect security cameras, sensors, routers, computers, switches, wireless access points and other network devices in your network application.

TAA-Compliant for GSA Schedule Purchases

The N252-048 is compliant with the Federal Trade Agreements Act (TAA), which makes it eligible for GSA (General Services Administration) Schedule and other federal procurement contracts.

Highlights

- Rated for 1 Gbps speeds for managing network connections in Ethernet applications
- 48 RJ45 ports numbered, labeled and color-coded for convenient wiring and ID
- Supports EIA/TIA T568A/B wiring standards for 110 punch-down terminations
- Mounts easily into 2U of space in your 19 in. rack for immediate use
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

Package Includes

N252-048 48-Port Cat6 Patch Panel

Specifications

OVERVIEW	
UPC Code	037332120045
Product Type	Rackmount
Technology	Cat5/5e; Cat6
CONNECTIONS	
Number of Ports	48



Powering Business Worldwide

TRIPP LITE
SERIES

Side A - Connector 1	110 IDC
Side B - Connector 1	RJ45 (FEMALE)
PoE Type	Type 2 PoE+ (30W, IEEE 802.3at)
PHYSICAL	
Color	Black
Shipping Dimensions (hwd / in.)	2.80 x 19.70 x 4.70
Shipping Dimensions (hwd / cm)	7.11 x 50.04 x 11.94
Shipping Weight (lbs.)	2.56
Shipping Weight (kg)	1.16
Unit Dimensions (hwd / in.)	2.100 x 18.900 x 1.000
Panel Style	Punchdown
STANDARDS & COMPLIANCE	
Product Compliance	Trade Agreements Act (TAA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.