


## Duplex Multimode 62.5/125 Fiber Adapter (LC-SC M/F) 1 ft. (0.31 m)

MODEL NUMBER: N458-001-62

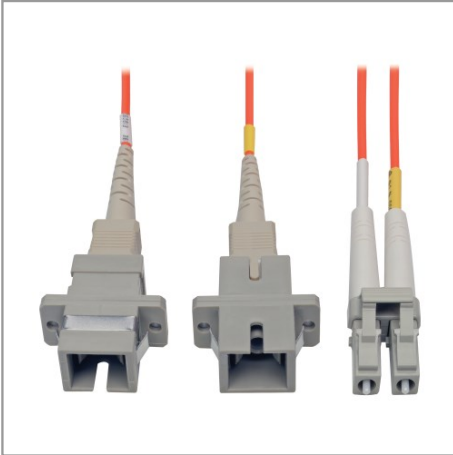

### Highlights

- Utilize Existing SC or ST Cabling with new LC type switches
- Available in 62.5/125 or 50/125 Micron
- LC/ST or LC/SC

### Package Includes

- LC/SC Duplex Multimode 62.5/125 Male-Female Fiber Adapter Cable, 1-ft. (0.31 m)

### Features

- Save money by utilizing older, existing fiber ST or SC cables with new LC installations
- Available in LC/ST or LC/SC in both 62.5/125 and 50/125 micron

## Specifications

OVERVIEW	
UPC Code	037332135391
Technology	Multimode
CONNECTIONS	
Side A - Connector 1	LC DUPLEX (MALE)
Side B - Connector 1	SC DUPLEX (FEMALE)
PHYSICAL	
Color	Orange
Clad Diameter (microns)	125
Core Diameter (microns)	62.5
Number of Fibers	2
Cable Length (ft.)	1
Cable Length (m)	0.30
Cable Length (in.)	12



Powering Business Worldwide

TRIPP LITE  
SERIES

Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Weight (lbs.)	0.04
Shipping Weight (kg)	0.02
<b>FEATURES &amp; SPECIFICATIONS</b>	
Push/Pull Tabs	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2026 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.