


## Toolless Horizontal 90-Degree T-Junction for Fiber Routing System, 120 mm (5 in.)

MODEL NUMBER: SRFC5JUNT

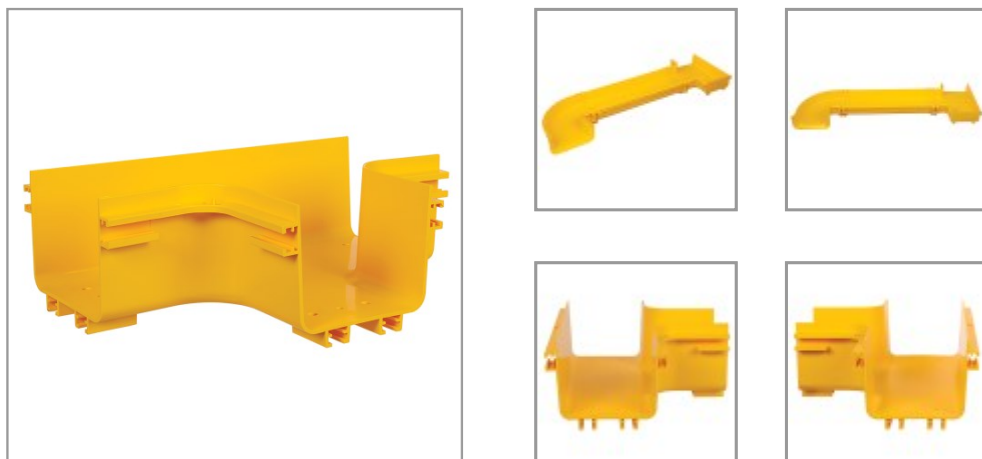

120 mm T-section turns a straight horizontal run in your fiber management system into a 90-degree horizontal branch.

### Features

#### High-Impact PVC T-Junction Helps You Create 90-Degree Fiber Cable Routing Branches

The SmartRack® SRFC5JUNT connects to three channel sections or other fittings in your fiber routing system to create a 90-degree horizontal branch. Three of SRFC5CPL5 couplers (sold separately) are required to complete your installation. Made from durable, lightweight PVC material, this T-section connects using the couplers' included hardware to help keep your fiber optic cable bundles neat and organized. Screws tighten by hand with no tools required to complete a professional, finished look in your data center, network closet or industrial space.

### Highlights

- Allows you flexibility in creating your custom fiber optic cable routing system
- Constructed from durable but lightweight PVC plastic
- Easy to install with your fiber routing system with no tools needed
- Requires 3 SRFC5CPL5 couplers (sold separately)

### Applications

- Create a fiber routing system along the wall or ceiling of your data center or network closet or across the tops of the rack enclosures

### System Requirements

- 3 x SRFC5CPL5 couplers (sold separately)

### Package Includes

- Horizontal 90° T-junction, 120 mm
- Installation guide

## Specifications

| OVERVIEW                               |                              |
|----------------------------------------|------------------------------|
| UPC Code                               | 037332240989                 |
| Product Type                           | Junction                     |
| Accessory Type                         | Cable Management Accessories |
| Cable Management System Component Type | Junction                     |
| PHYSICAL                               |                              |
| Color                                  | Yellow                       |
| Shipping Dimensions (hwd / in.)        | 14.56 x 10.63 x 5.11         |
| Shipping Weight (kg)                   | 0.96                         |
| Unit Dimensions (hwd / in.)            | 4.645 x 13.900 x 10.100      |
| Unit Dimensions (hwd / cm)             | 11.8 x 35.31 x 25.65         |



Powering Business Worldwide

TRIPP LITE  
SERIES

|                                     |                         |
|-------------------------------------|-------------------------|
| Unit Weight (lbs.)                  | 1.466                   |
| Unit Weight (kg)                    | 0.66                    |
| STANDARDS & COMPLIANCE              |                         |
| Product Compliance                  | RoHS; EIA/ECA-310-E     |
| WARRANTY & SUPPORT                  |                         |
| Product Warranty Period (Worldwide) | 5-year limited warranty |

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.