


## SmartRack Outdoor Industrial Enclosure with Lock - NEMA 4, Surface Mount, Metal Construction, 10 x 10 x 6 in., Yellow

MODEL NUMBER: **SRIN410106Y**

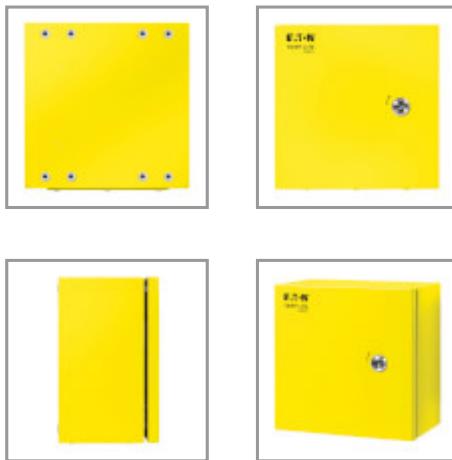

Locking metal enclosure protects your outdoor equipment against theft, damage, tampering, and excess moisture and debris.

### Features

#### Surface-Mount Enclosure Secures and Organizes Valuable First-Responder Equipment

This SmartRack® industrial enclosure with a yellow metal housing is designed to protect expensive outdoor equipment, especially that used in security, fire, law enforcement and other first-responder applications. It accommodates industrial controls and computers, HMI, enterprise systems, remote networking equipment, distributed controls, production monitoring systems, wireless access points, building automation and HVAC, security, audio/video, and telecommunications applications. Included steel and plastic rear panels accommodate most equipment.

#### NEMA 4 Enclosure Designed for Protection Against Harsh Elements

The SRIN410106Y protects its contents against the ingress of water (including rain, sleet, snow, splashing water and hose-directed water), solid foreign objects (including falling dirt and windblown dust) and even ice forming on the outside of the enclosure. It is ideal for a multitude of industrial sites, such as factories, processing plants, fabrication areas, retail locations and other areas where you need to keep sensitive equipment secure, organized and out of the way.

#### Locks Securely to Help Prevent Theft, Damage and Tampering

The rugged heavy-duty 14-gauge steel housing locks securely with the included key to protect its contents against theft, tampering, dust and other contaminants. The weather-sealed door allows easy access to equipment and cabling during installation and maintenance. Data and power cables may be routed through a bottom conduit cutout.

#### Easy to Install

This steel enclosure comes fully assembled and ready for mounting on a wall using both the included and user-supplied hardware. It measures 10 inches high, 10 inches wide and 6 inches deep.

## Specifications

### OVERVIEW

### Highlights

- Yellow metal housing protects security, fire, law enforcement and other equipment
- NEMA 4 enclosure provides protection against water, ice, snow and other moisture
- Includes metal and plastic backplates to accommodate a wide range of equipment
- Comes fully assembled and ready for wall mounting using included hardware

### Package Includes

- SRIN410106Y Outdoor Industrial Enclosure
- (4) Mounting brackets
- (8) M6 screws
- Information/data filing door bracket
- Metal backplate
- Plastic backplate
- Gland plate (pre-installed)
- Key
- Installation guide



Powering Business Worldwide

TRIPP LITE  
SERIES

UPC Code	037332283078
Device Compatibility	Patch Panel; Network Switch
Rack Type	Enclosure; Small Enclosure
<b>PHYSICAL</b>	
Color	Yellow
Material of Construction	Powder Coated Steel
Rack Height	5U
Rack Depth	Shallow
Mounting Location	Wall; Pole
Mounting Holes or Slots	Yes
Maximum Device Depth (cm)	22.86
Maximum Device Depth (in.)	9
Maximum Device Depth (mm)	229
Shipping Form Factor	Factory Assembled
Shipping Dimensions (hwd / in.)	12.40 x 12.40 x 12.40
Shipping Weight (kg)	10.50
Unit Dimensions (hwd / in.)	10.000 x 10.000 x 6.000
Unit Dimensions (hwd / cm)	25.4 x 25.4 x 15.24
Unit Dimensions (in.)	10 x 10 x 6
Unit Weight (lbs.)	17.64
Unit Weight (kg)	8.00
Weight Capacity - Stationary (kg)	91
Weight Capacity - Stationary (lbs.)	200
Number of Vertical Mounting Rails	4
Mounting Details	Plastic and metal mounting panel, document holder
Cable Entry/Exit	Cut-out with removable cover
<b>FEATURES &amp; SPECIFICATIONS</b>	
Grounding Details	Cabinet Body
Tools Necessary	Yes
Built-in Cable Management	No
Extra Wide	No
Locking	Yes
Lock Type	Key
Pre-Installed Casters	No
Outdoor Use	Yes



Powering Business Worldwide

TRIPP LITE  
SERIES

Gasketed Door	Yes
<b>STANDARDS &amp; COMPLIANCE</b>	
Protection Rating	NEMA 4
Product Certifications	CAN/CSA-C22.2 No. 286 (Canada); CAN/CSA-C22.2 No. 94 (Canada); UL 50; UL 508A
Product Compliance	NEMA 4; RoHS; REACH
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.