


SmartRack Center-Mounted Steel Rack Shelf - 2U, Vented, 21.5 in. Deep, Holds up to 100 lb. (45 kg)

MODEL NUMBER: SRSHELF2PCENTER

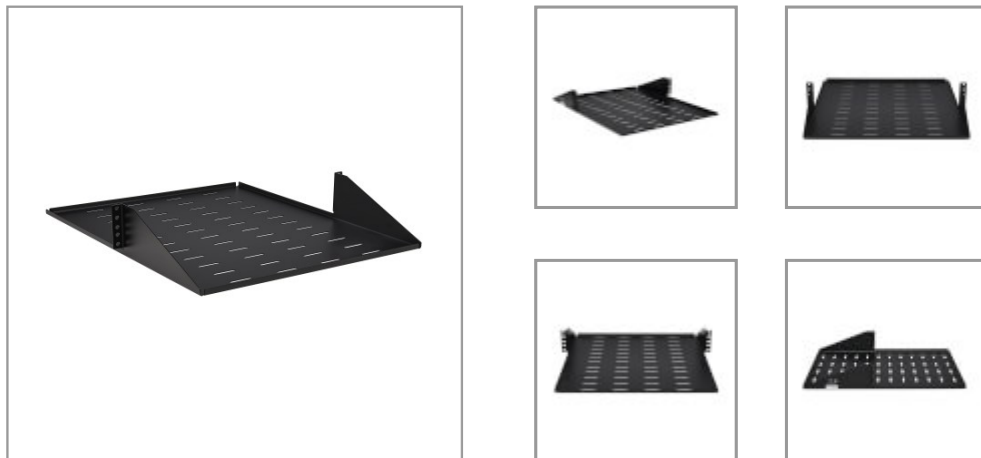

Vented shelf is 21.5 in. deep to house a wireless access point or other non-rack device and save space in your server room or network closet.

Features

2U Vented Rack Shelf Secures Non-Rack Equipment in Your Data Center

This SmartRack® center-mount shelf supports monitors, wireless access points, tower units and other IT equipment not typically stored in a rack. Made from heavy-duty cold-rolled steel with a durable black powder-coated finish, the SRSHELF2PCENTER has a maximum load capacity of 100 pounds (45 kgs). It mounts easily into 2U of space in a standard 3-inch-deep 2-post open frame rack using the included hardware.

Maximizes Rack Space and Saves Desk or Floor Space in a Busy Office

The steel shelf is 21.5 inches (55 cm) deep for organizing network and other non-rack equipment in your small office or server room. The vented surface allows generous airflow to keep your equipment cool and functioning at its peak.

Highlights

- Center-mount 2U rack shelf secures non-rack equipment like WAPs and monitors
- Heavy-duty cold-rolled steel construction with maximum load capacity of 100 lb.
- Vented design maximizes airflow to protect equipment against excessive heat
- Easy to install centered in a standard 3 in. 2-post rack with included hardware

Package Includes

- SRSHELF2PCENTER 2U Center-Mount Shelf, 21.5 in. Deep (55 cm)
- (4) 12-24 screws
- (4) Cup washers
- Instruction sheet

Specifications

OVERVIEW	
UPC Code	037332263179
Product Type	Accessories / Shelf
Device Compatibility	Network Switch; Router
Accessory Type	Rack Shelves
Accessory Class	Rack Accessories
PHYSICAL	
Rack Height	2U



Powering Business Worldwide

TRIPP LITE
SERIES

Maximum Weight Capacity (lbs.)	100
Maximum Weight Capacity (kg)	45
Unit Dimensions (hwd / in.)	3.460 x 19.000 x 21.570
Unit Dimensions (hwd / cm)	8.79 x 48.26 x 53.34
Unit Weight (lbs.)	7.00
Unit Weight (kg)	3.18
FEATURES & SPECIFICATIONS	
IP68 Rated	No
IP20 Rated	No
Built-in Cable Management	No
Extra Wide	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; EIA/ECA-310-E
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.