


Protect It! 10-Outlet Surge Protector with Swivel Light Bars - 5-15R Outlets, 2 USB Ports, 10 ft. (3 m) Cord, 4500 Joules, Black

MODEL NUMBER: **TLP1010USB**

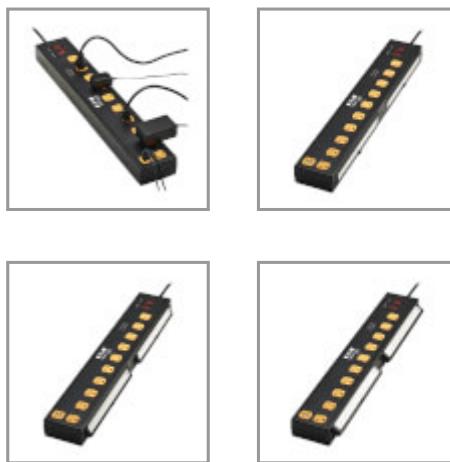

Protects your lab equipment, industrial tools and other electronics against power surges, spikes and line noise.

Features

10-Outlet Surge Protector Safeguards Your Sensitive Electronics

Ideal for your home, office, retail or industrial workstation, this Protect It!® surge protector features a 4500 joule rating to defend your valuable electronic components against damaging power surges and spikes. The 10-foot (3-meter) AC input cord with NEMA 5-15P plug gives you flexibility in placing the surge protector away from the nearest wall outlet.

NEMA 5-15R Outlets Accept a Wide Range of Electronic Devices

Plug your computer, wireless router, power tools, laboratory equipment and other home/office/industrial electronics into 10 NEMA 5-15R outlets to protect them against dangerous surges, spikes and line noise. The outlets are adequately spaced apart to accommodate bulky transformers without blocking adjacent receptacles.

Premium Protection from EMI/RFI Line Noise Helps Your Equipment Perform Better

This surge protector filters out disruptive EMI (electromagnetic interference) and RFI (radio frequency interference) line noise that can disturb your electronics and inflict hardware damage or data loss. This EMI/RFI filtering also helps your connected components perform better and last longer.

Swivel Light Bars Brighten Your Workspace

Two adjustable light bars, each with 1000 lumens (20W), provide bright white light to illuminate any dark corners.

USB Charger Offers Easy Access to Mobile Devices

Two USB-A ports share 2.4A for charging your smartphone, tablet and other USB mobile devices.

Includes the Latest Safety Features to Maintain Your Equipment's Well-Being

Two lighted on/off switches allow easy one-touch control over the light bars and all equipment connected to the surge protector. Integrated 15A resettable circuit breakers help prevent equipment damage due to overloads. Diagnostic LEDs let you know that the wall outlet is grounded and that your equipment is protected.

Flexible Installation Options

Place the TLP1010USB on any flat surface in your home, office, workbench or anywhere else you need

Highlights

- 10 NEMA 5-15R outlets distribute AC power to connected home/office/work equipment
- 4500 joules protect your valuable electronics against dangerous surges and spikes
- Swivel LED light bars provide 1000 lumens each to illuminate dark corners
- 10 ft. input cord allows great flexibility in placing devices away from wall outlet
- On/off switches give you one-touch control over lights and connected equipment

Package Includes

- TLP1010USB 10-Outlet Surge Protect
- Owner's manual

power for your equipment. Integrated rear keyhole slots accommodate wall or desktop mounting.

Specifications

OVERVIEW	
UPC Code	037332283276
Product Type	Surge Protector
Charging Form Factor	Strip
Device Compatibility	Amazon Kindle; Chromebook; Computer; Laptop; Phone; Printer; Tablet
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V (110-125V)
Input Cord Gauge Type	14 gauge; SJT
Input Cord Gauge (AWG)	14
Voltage Compatibility (VAC)	120
Input Plug Type	NEMA 5-15P
Input Cord Details	SJT
Input Cord Length (ft.)	10
Right-Angle Plug	No
Input Cord Length (m)	3.05
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	60 Hz
Output (Watts)	1875
Output Receptacles	(10) 5-15R
Circuit Breaker (amps)	15
Transformer Accommodation	(10) Yes
Outlet Orientation	Single row of outlets
Right-Angle Outlets	Yes
USER INTERFACE, ALERTS & CONTROLS	
Diagnostic LED(s)	Yes
Switches	Combination AC circuit breaker and 2 position on/off power switch
Diagnostic LED Details	Built-in LED confirms suppressor "protection present" (green) status, "grounded status (red)

CHARGING	
Number of Charging Ports	2
Total Charging Amps	2.4A
Total Charging Watts	12
Charging Method	USB
Charging Port Type	(2) USB A (FEMALE)
Charging Ports / Amps	(2) 2.4A
Overcharge Protection	No
Charging Amps per Port	2.4A
LIGHTING	
Number of Light bars	2
Light bar Color	Bright White
Light bar Brightness	1000 lumens (20W)
SURGE / NOISE SUPPRESSION	
AC Suppression Joule Rating	4500
AC Suppression Response Time	< 1 ns
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G) line suppression
UL1449 Let Through Rating	600V
EMI / RFI Filtering	Yes 150KHz - 100MHz
Automatic Shut-Off	No
DATALINE SURGE SUPPRESSION	
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
Telephone/DSL Protection	No
PHYSICAL	
Material of Construction	Plastic
Power Cord Color	Black
Housing Color	Black
Mounting Holes or Slots	Yes
Receptacle Color	Yellow
Shipping Dimensions (hwd / in.)	26.20 x 6.20 x 2.40
Shipping Dimensions (hwd / cm)	66.55 x 15.75 x 6.10
Shipping Weight (lbs.)	3.80



Powering Business Worldwide

TRIPP LITE
SERIES

Shipping Weight (kg)	1.72
Unit Dimensions (hwd / in.)	24.600 x 6.100 x 2.040
Unit Dimensions (hwd / cm)	62 x 14 x 5.2
Unit Weight (lbs.)	2.84
Unit Weight (kg)	1.29
Input Cord Color	Black
ENVIRONMENTAL	
Operating Temperature Range	32° to 104°F (0° to 40°C)
Storage Temperature Range	5° to 104°F (-15° to 40°C)
Operating Humidity Range	20% to 85% RH
Storage Humidity Range	0% to 90% RH
FEATURES & SPECIFICATIONS	
Rotatable Outlets	No
Antimicrobial	No
GaN Technology	No
STANDARDS & COMPLIANCE	
Product Certifications	CAN/CSA-C22.2 No. 269.3 (Canada); CAN/CSA-C22.2 No. 308 (Canada); UL 1363; UL 1449; UL Listed; cUL Listed
Product Compliance	FCC Part 15 Class B (USA); RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty
Connected Equipment Insurance (U.S., Canada & Puerto Rico)	\$150,000 Ultimate Lifetime Insurance

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.