


PRODUCT DATA DRAWING

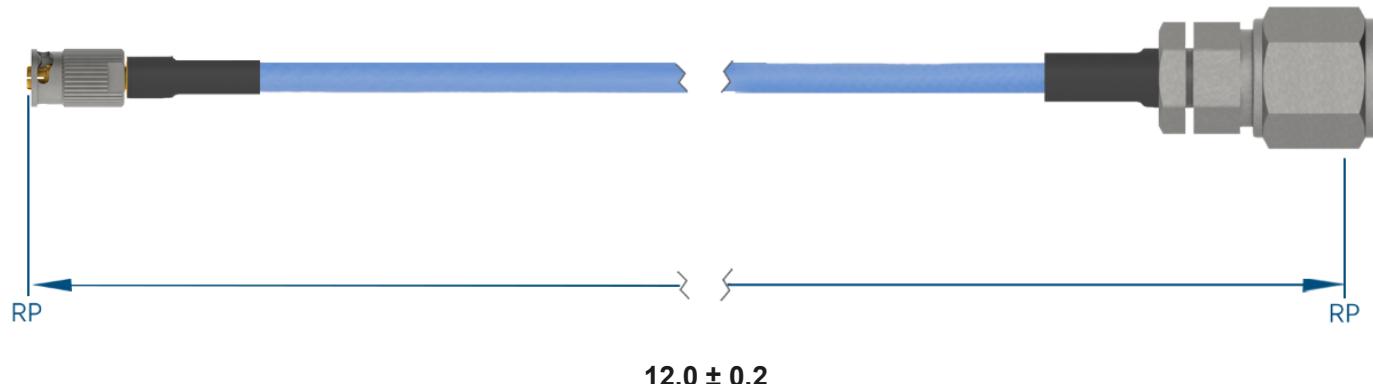

MATERIAL

CONNECTORS: SMPM Female QB ([3221-60004](#))
1.85mm Straight Male ([SF3311-60003](#))
CABLE: Ø.085 Flexible Coax
SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms
FREQ. RANGE: DC to 65 GHz
VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz
INSERTION LOSS: 2.92 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:
SMPM Female QB to 1.85mm Straight Male 12" Cable
Assembly for Ø.085 Flexible Coax

DWG. NO.
[FQSMPM-085-MS185-120](#)

DRAWN
2022-10-18 11:32:17