


Fiber Optic Trunk Cable

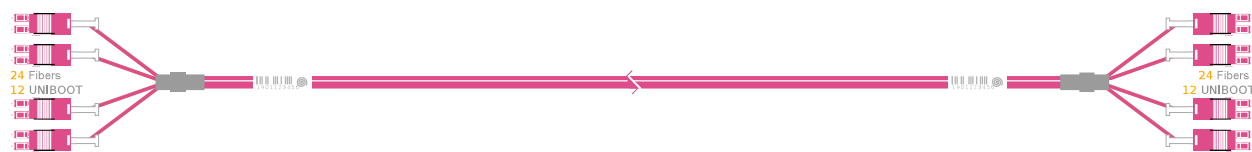

Connector Side A



Cable cross-section scheme



Connector Side B

Connector Side A		Connector Side B	
LC/UPC Multimode UNIBOOT WITH TAB	Connector Description Design Specification Manufacturer Ferrule Operation Temperature Material of Ferrule Plug Cycles Typical Insertion Loss (IL) Bend Protection Dividing Element Whip	LC/UPC Multimode UNIBOOT WITH TAB	IEC 61754-20, JIS C 5964-20, Telcordia GR 326 CORE Seikoh Giken Ø1.25mm, ceramics, axial suspended -40°C to +75°C Plastic/ heather violet 500 ≤ 0.20 dB white 12-times Dividing element M25 0.60m
IEC 61754-20, JIS C 5964-20, Telcordia GR 326 CORE			
Seikoh Giken			
Ø1.25mm, ceramics, axial suspended			
-40°C to +75°C			
Plastic/ heather violet			
500			
≤ 0.20 dB			
white			
12-times Dividing element M25			
0.60m			
Cable			
Cable Type	U-DQ(ZN)BH	Manufacturer	Leoni
Number of Fibers	24	Fiber Class	OM4 BI
Outer diameter	7.5mm	Cable Color	heather violet
Cloak Material	FRNC	Pull Strength	1750N
Cable Weight	60Kg/km	Operation Temperature	-20°C to +60°C
CPR classification	CPR Dca		