

1

2

3



4

5


6

7

RoHS Compliant

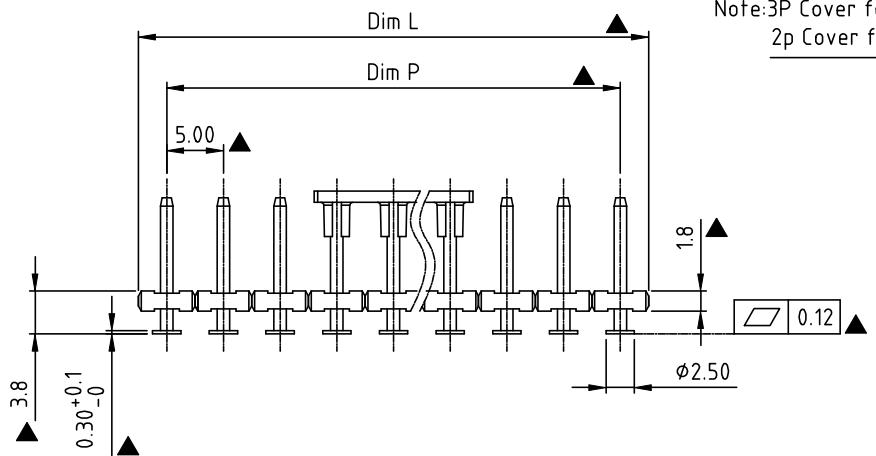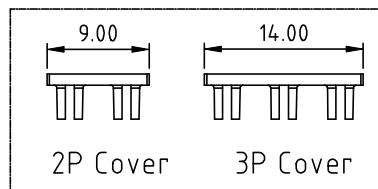

Note: 3P Cover for odd poles
2P Cover for even poles

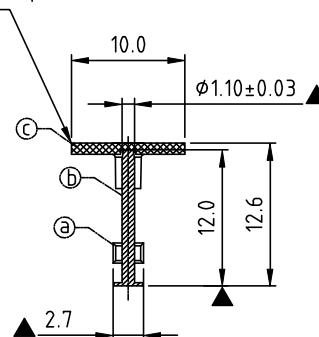

Material:

- Item ③ Terminal(housing): PA46 (UL94V-0)
- Item ⑤ Male contact pin: Brass, Matte tin plated over Nickel plated
- Item ④ Terminal(cover): PA46 (UL94V-0)

Electrical:

- Voltage rating: 300V
- Current rating: 15A
- Withstanding Voltage: 1.6KV
- Operating temperature: -40°C to +120°C
- Reflow soldering temperature: 260°C/10 Sec Max
- Critical dimension: ▲

GW xx 0 8 0 0 0 0 0 0 G


G RoHS compliant
(lead<4%)
In copper Alloy

POLES

02 pole

" " " "

12 pole

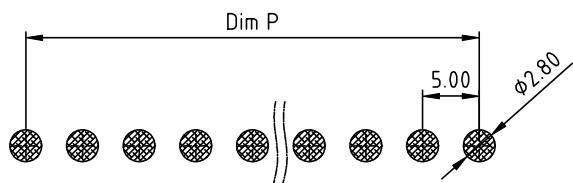

P.C.B. LAYOUT

N = Number of poles

Dim L=Nx5.0

Dim P=(N-1)x5.0

POLES	Dim L	Dim P
2-5p	±0.10	±0.10
6-9p	±0.15	±0.15
10-12p	±0.20	±0.20

Amphenol
ANYTEK

CUSTOMER COPY

ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR, PROPERTY OF ANYTEK TECHNOLOGY CO., LTD

TITLE	GW 5.0 Series (L=12.0mm,Φ1.10) (Tape reel packing and vacuum packaging)			DWG NO.	8GW0011	
PART NO.	GWxx08000000G			CUST NO.		
APPROVED	CHECKED	DESIGNED	DRAWN			
		Chen Bo 12/15/20	Chen Bo 10/28/20		UNIT: mm SCALE: NONE SHEET: 01/01	Tolerance X. ±0.50 X.X. ±0.30 X.XX. ±0.10 X° ±1°