


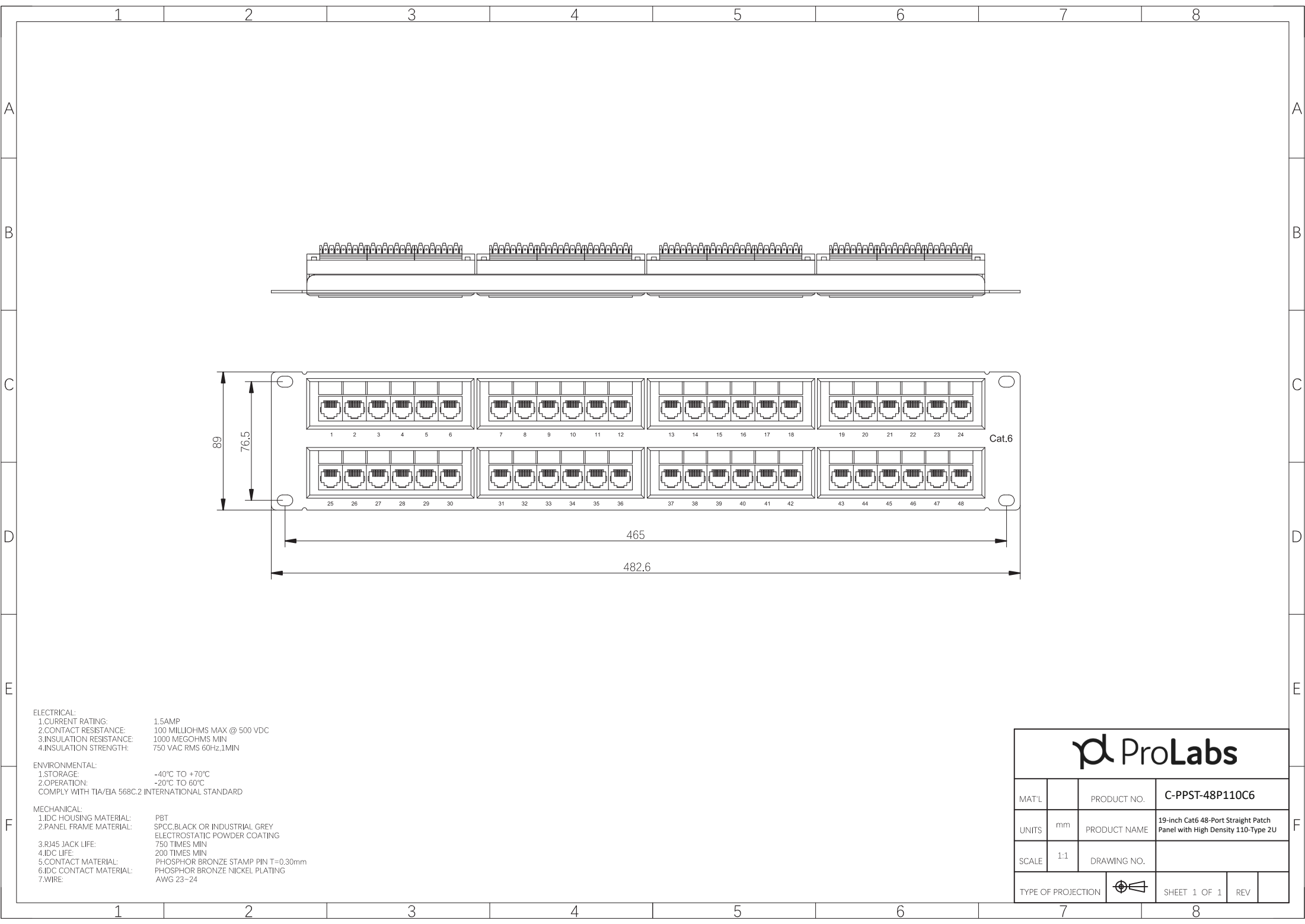

ELECTRICAL:
1.CURRENT RATING: 1.5AMP
2.CONTACT RESISTANCE: 100 MILLIOHMS MAX @ 500 VDC
3.INSULATION RESISTANCE: 1000 MEGOHMS MIN
4.INSULATION STRENGTH: 750 VAC RMS 60Hz,1MIN

ENVIRONMENTAL:
1.STORAGE: -40°C TO +70°C
2.OPERATION: -20°C TO 60°C
COMPLY WITH TIA/EIA 568C.2 INTERNATIONAL STANDARD

MECHANICAL:
1.IDC HOUSING MATERIAL: PBT
2.PANEL FRAME MATERIAL: SPCC,BLACK OR INDUSTRIAL GREY ELECTROSTATIC POWDER COATING
3.RJ45 JACK LIFE: 750 TIMES MIN
4.IDC LIFE: 200 TIMES MIN
5.CONTACT MATERIAL: PHOSPHOR BRONZE STAMP PIN T=0.30mm
6.IDC CONTACT MATERIAL: PHOSPHOR BRONZE NICKEL PLATING
7.WIRE: AWG 23-24

ProLabs					
MAT'L		PRODUCT NO.	C-PPST-48P110C6		
UNITS	mm	PRODUCT NAME	19-inch Cat6 48-Port Straight Patch Panel with High Density 110-Type 2U		
SCALE	1:1	DRAWING NO.			
TYPE OF PROJECTION			SHEET 1 OF 1	REV	