


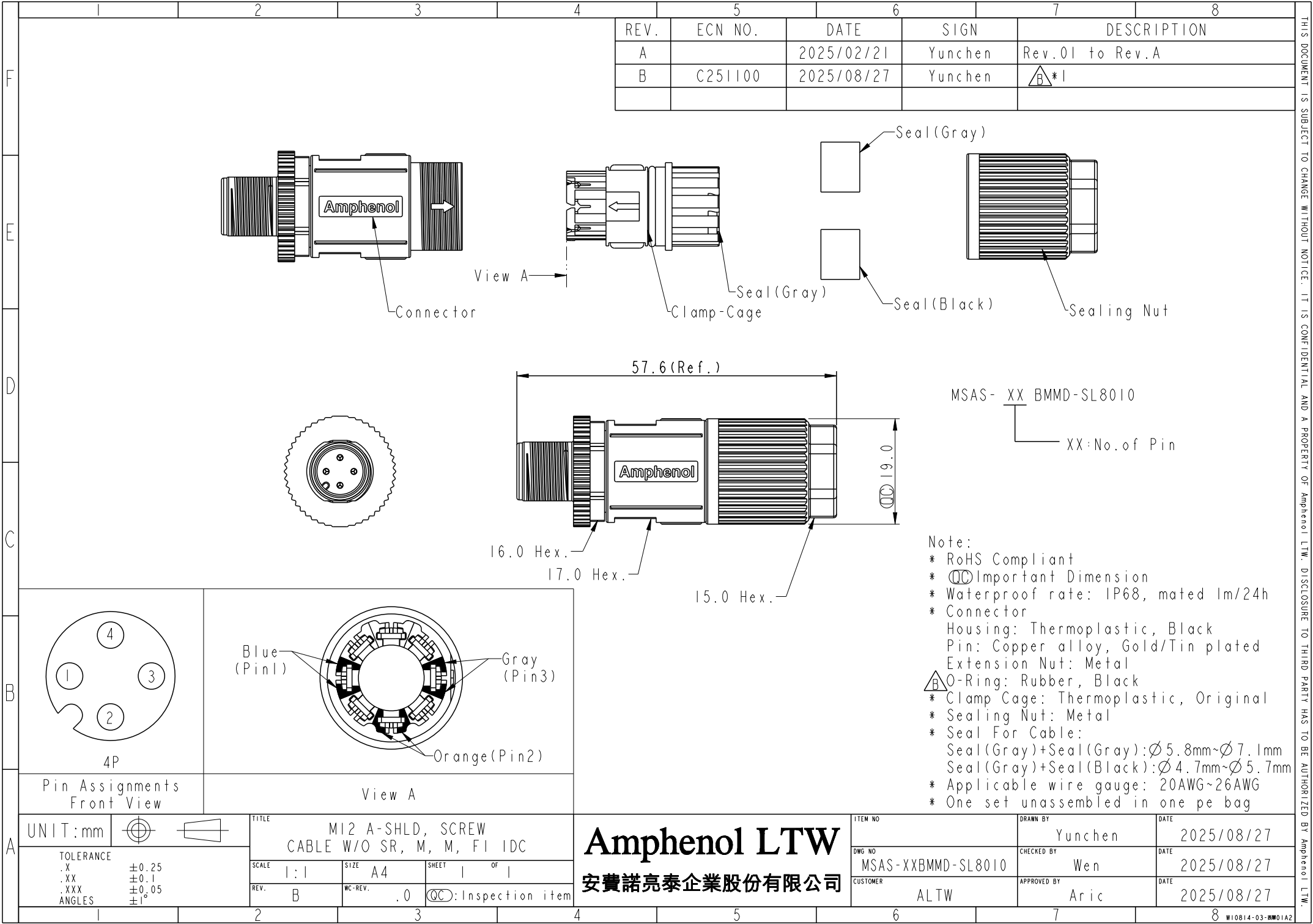

Note:

- * RoHS Compliant
- *  Important Dimension
- * Waterproof rate: IP68, mated 1m/24h
- * Connector
- Housing: Thermoplastic, Black
- Pin: Copper alloy, Gold/Tin plated
- Extension Nut: Metal
-  O-Ring: Rubber, Black
- * Clamp Cage: Thermoplastic, Original
- * Sealing Nut: Metal
- * Seal For Cable:
 - Seal (Gray)+Seal (Gray): $\varnothing 5.8\text{mm}\sim\varnothing 7.1\text{mm}$
 - Seal (Gray)+Seal (Black): $\varnothing 4.7\text{mm}\sim\varnothing 5.7\text{mm}$
- * Applicable wire gauge: 20AWG~26AWG
- * One set unassembled in one pe bag

THIS DOCUMENT IS SUBJECT TO CHANGE WITHOUT NOTICE. IT IS CONFIDENTIAL AND A PROPERTY OF Amphenol LTW. DISCLOSURE TO THIRD PARTY HAS TO BE AUTHORIZED BY Amphenol LTW.