


3-phase busbar for 4 circuit breakers size S2 modular spacing 55 mm

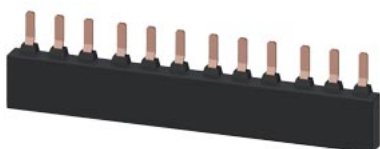

|                          |                       |
|--------------------------|-----------------------|
| product brand name       | SIRIUS                |
| product category         | Infeed systems        |
| product designation      | 3-phase busbar        |
| product type designation | 3RV19                 |
| suitability for use      | circuit-breakers 3RV2 |

| General technical data                                  |            |
|---------------------------------------------------------|------------|
| size of the circuit-breaker                             | S2         |
| protection class IP on the front according to IEC 60529 | IP20       |
| thermal current                                         | 108 A      |
| Substance Prohibittance (day/month/year)                | 07/01/2006 |
| Net Weight                                              | 0.273 kg   |
| number of poles for main current circuit                | 3          |
| operating voltage at AC rated value                     | 690 V      |
| operational current rated value                         | 108 A      |

| UL/CSA ratings                                          |                                                  |
|---------------------------------------------------------|--------------------------------------------------|
| operating voltage at AC according to UL rated value     | 600 V                                            |
| Electrical Safety                                       |                                                  |
| protection class IP on the front according to IEC 60529 | IP20                                             |
| touch protection on the front according to IEC 60529    | finger-safe, for vertical contact from the front |

| Connections/ Terminals                                 |                      |
|--------------------------------------------------------|----------------------|
| type of electrical connection for main current circuit | screw-type terminals |

| Approvals Certificates |  |  |
|------------------------|--|--|
|------------------------|--|--|

| Environment | General Product Approval | Test Certificates |
|-------------|--------------------------|-------------------|
|-------------|--------------------------|-------------------|

[Environmental Con-  
firmations](#)



[Special Test Certific-  
ate](#)

| Test Certificates | Maritime application |
|-------------------|----------------------|
|-------------------|----------------------|

[Type Test Certific-  
ates/Test Report](#)



| Maritime application | other | Railway |
|----------------------|-------|---------|
|----------------------|-------|---------|



[Miscellaneous](#)

[Confirmation](#)



[Special Test Certificate](#)

#### Further information

##### Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

##### Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

##### Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

##### Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RV1935-1C>

##### Cax online generator


<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RV1935-1C>

##### Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RV1935-1C>

##### Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

[https://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=3RV1935-1C&lang=en](https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RV1935-1C&lang=en)

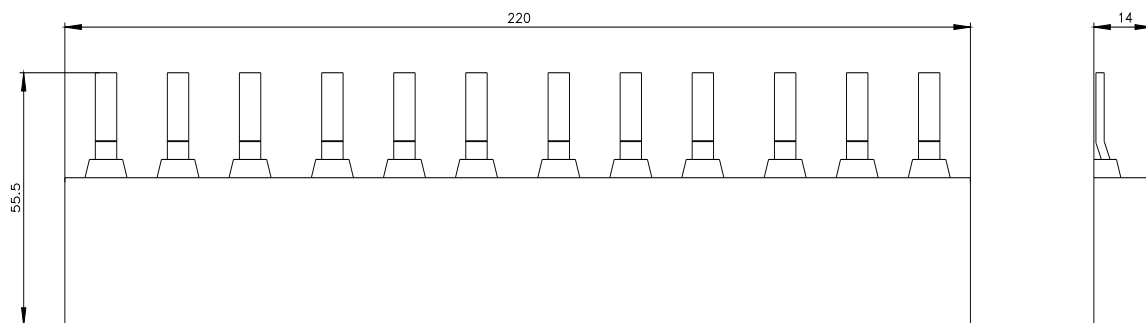

last modified:

10/18/2025