

Fork lever for position switch 3SE51 2 x lever made of metal with one stainless steel roller 19 mm each for actuator head 3SE5000-0AT10



product brand name	SIRIUS		
product designation	actuator for fork lever actuator		
product type designation	3SE5		
manufacturer's article number	3SE5000-0AT02		
of the supplied operating lever			
General technical data			
product function positive opening	Yes		
shock resistance	30 g / 11 ms		
according to IEC 60068-2-27			
vibration resistance	0.35 mm/5 g		
according to IEC 60068-2-6			
mechanical service life (operating cycles) typical	1 000 000		
reference code according to IEC 81346-2	T		
active principle	mechanical		
Substance Prohibitance (day/month/year)	07/01/2006		
Net Weight	0.055 kg		
minimum actuating torque in directions of actuation	0.25 N·m		
Ambient conditions			
ambient temperature	-25 ... +85 °C		
during operation			
during storage	-40 ... +90 °C		
explosion protection category for dust	none		
Enclosure			
coating of the enclosure	Other types		
Drive Head			
design of the actuating element	metal lever, stainless steel rollers 19 mm, one track		
shape of the switch head	roller		
outer diameter of the switch head	19 mm		
Installation/ mounting/ dimensions			
mounting position	any		
fastening method	lockable plug-in fixing		
design of the interface for safety-related communication	without		
Communication/ Protocol			
design of the interface	without		
Approvals Certificates			
General Product Approval		Test Certificates	other



[Type Test Certificates/Test Report](#)

[Confirmation](#)

other

Environment



[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3SE5000-0AT02>

Cax online generator



<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3SE5000-0AT02>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3SE5000-0AT02>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3SE5000-0AT02&lang=en

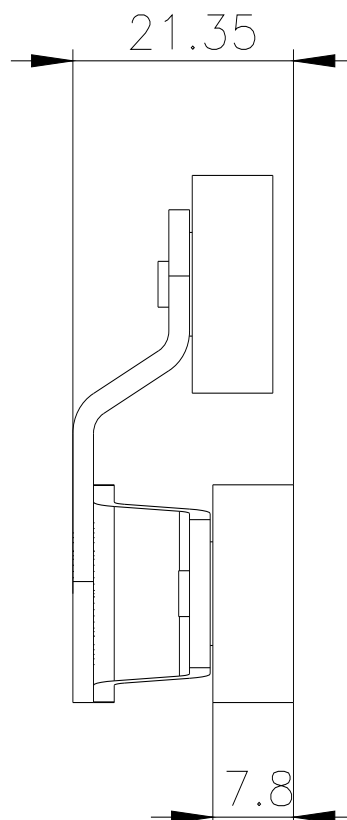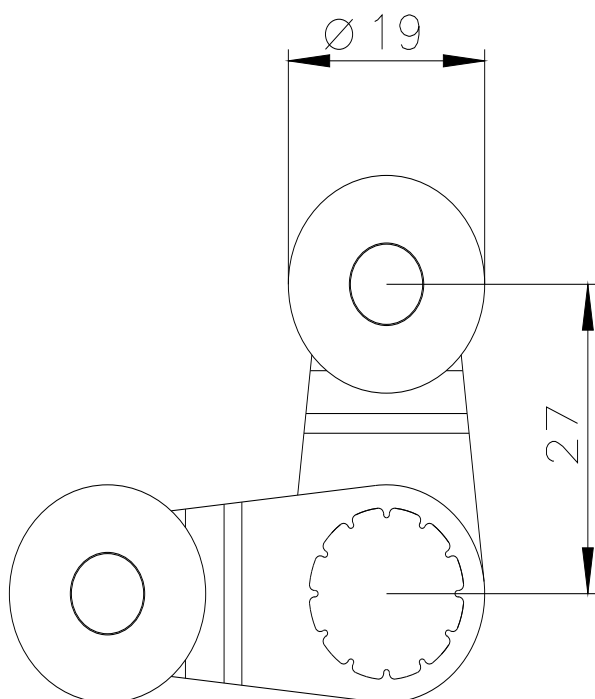

last modified:

4/4/2026