



circular conduc. terminal TA4.4 4 x 120...300 mm² with aux. conductor voltage tap for 4 cables; 4 units accessory for: 3VA15; 3VA25

Model	
product brand name	SETRON
product designation	circular conductor terminal
design of the product	Connection method
accessories	Wire connector
General technical data	
designation / of the terminal	TA4.4
type of electrical connection / with control wire tap	Yes
Mechanical Design	
Net Weight	3.617 kg
Connections according IEC	
connectable conductor cross-section	
• for copper cable / stranded / minimum	120 mm ²
• for copper cable / stranded / maximum	300 mm ²
• for aluminum cable / stranded / minimum	120 mm ²
• for aluminum cable / stranded / maximum	300 mm ²
stripped length	28,7 / 56,1 mm
tightening torque / when using copper cables	
• stranded	120 - 300 mm ² : 42.4 Nm
• finely stranded	150 ... 185 mm ² 42.4 Nm
• finely stranded / with core end processing	150 - 185 mm ² : 42.4 Nm
Connetctions according UL	
permissible temperature / of connectable conductor / according to UL 486A-486B	90 °C
stripped length	1.13 / 2.21 in
connectable conductor cross-section	
• for copper cable / stranded / minimum	4/0 AWG
• for copper cable / stranded / maximum	600 kcmil
• for aluminum cable / stranded / minimum	4/0 AWG
• for aluminum cable / stranded / maximum	600 kcmil
tightening torque / when using copper cables	
• stranded	4/0 - 600 kcmil: 375 lb-in
Certificates	
General Product Approval	EMV

[Miscellaneous](#)




[Confirmation](#)



Test Certificates	Maritime application	other	Environment		
Type Test Certificates/Test Report		Miscellaneous	Confirmation	Environmental Confirmations	Environmental Confirmations

Further information

- Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
- Information for data generation and storage
<https://support.industry.siemens.com/cs/ww/en/view/109995012>
- Information- and Downloadcenter (Catalogs, Brochures,...)
<https://www.siemens.com/lowvoltage/catalogs>
- Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9604-0JC44>
- Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/3VA9604-0JC44>
- Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
https://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9604-0JC44
- CAX-Online-Generator
<https://www.siemens.com/cax>
- Tender specifications
<https://www.siemens.com/specifications>

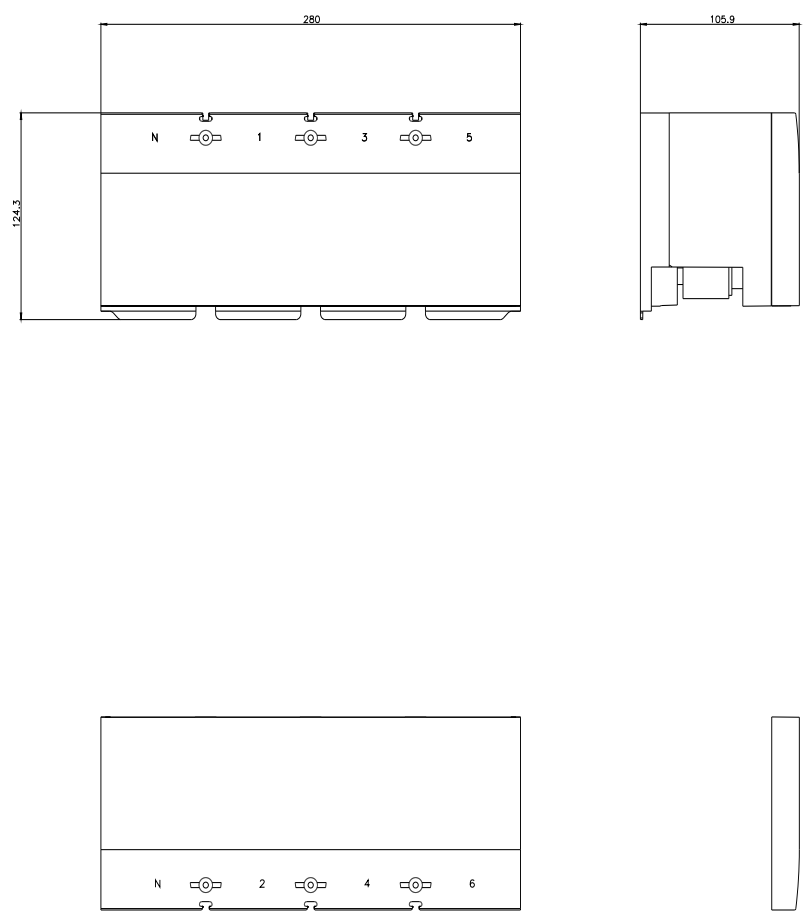

last modified: 4/6/2026 

