

LED, base BA15d, green, 24 V AC/DC, accessory for signaling columns, with diameter 50 mm and 70 mm



Figure similar

product brand name	SIRIUS
product designation	LED
General technical data	
type of voltage of the operating voltage	AC/DC
operating voltage	
• 1 at DC rated value	24 V
• 1 at AC at 50 Hz rated value	24 V
• 1 at AC at 60 Hz rated value	24 V
relative positive tolerance of the operating voltage	10 %
relative negative tolerance of the operating voltage	-15 %
consumed current maximum	15 mA
reference code according to EN 61346-2	P
Lamp	
type of light source	LED
light intensity	1.05 cd
design of the reflection body	Drum lens
socket design	BA 15d
Enclosure	
height	45 mm
width	20 mm
outer diameter of the signal column element	70 mm
color	green
Ambient conditions	
ambient temperature during operation	-20 ... +60 °C
Environmental footprint	
Environmental Product Declaration (EPD)	Yes
Siemens eco profile (SEP)	Siemens EcoTech
Approvals Certificates	
General Product Approval	other



[Confirmation](#)



EG-Konf.



[Confirmation](#)





Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8WD4428-6XC>

Cax online generator

<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD4428-6XC>


Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8WD4428-6XC>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=8WD4428-6XC&lang=en

-P

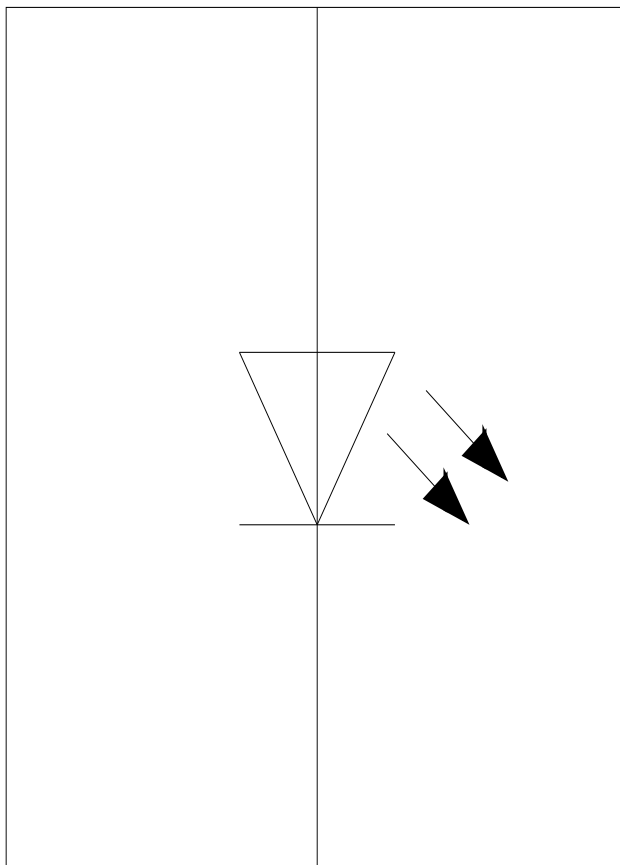

last modified:

7/15/2026