



Flashlight element, with integrated LED, yellow, 115 V AC, Diameter 70 mm

|                                                      |                              |
|------------------------------------------------------|------------------------------|
| product brand name                                   | SIRIUS                       |
| product designation                                  | Repeated-flash light element |
| design of the product                                | including light sources      |
| <b>General technical data</b>                        |                              |
| type of voltage of the operating voltage             | AC                           |
| operating voltage                                    |                              |
| • 1 at AC at 50 Hz rated value                       | 115 V                        |
| • 1 at AC at 60 Hz rated value                       | 115 V                        |
| relative positive tolerance of the operating voltage | 10 %                         |
| relative negative tolerance of the operating voltage | -10 %                        |
| consumed current maximum                             | 25 mA                        |
| reference code according to EN 61346-2               | P                            |
| <b>Lamp</b>                                          |                              |
| type of light source                                 | LED                          |
| light intensity                                      | 0.74 cd                      |
| light intensity                                      | 0.5 ... 1.05 cd              |
| design of the reflection body                        | Drum lens                    |
| flashing frequency                                   | 1 Hz                         |
| product component light source                       | Yes                          |
| service life of LED                                  | 100 000 h                    |
| design of the optical signal                         | blinklight                   |
| <b>Enclosure</b>                                     |                              |
| height                                               | 65.5 mm                      |
| width                                                | 70 mm                        |
| outer diameter of the signal column element          | 70 mm                        |
| material                                             | PC                           |
| color                                                | yellow                       |
| fastening method                                     | Bayonet                      |
| protection class IP                                  | IP65                         |
| <b>Ambient conditions</b>                            |                              |
| ambient temperature during operation                 | -20 ... +50 °C               |
| <b>Environmental footprint</b>                       |                              |
| Environmental Product Declaration (EPD)              | Yes                          |
| Siemens eco profile (SEP)                            | Siemens EcoTech              |
| <b>Approvals Certificates</b>                        |                              |
| General Product Approval                             | other                        |



[Confirmation](#)



[Confirmation](#)

other

Environment



[Environmental Confirmations](#)



Siemens  
EcoTech



#### Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8WD4440-5BD>

Cax online generator



<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD4440-5BD>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)


<https://support.industry.siemens.com/cs/ww/en/ps/8WD4440-5BD>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

[https://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=8WD4440-5BD&lang=en](https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=8WD4440-5BD&lang=en)

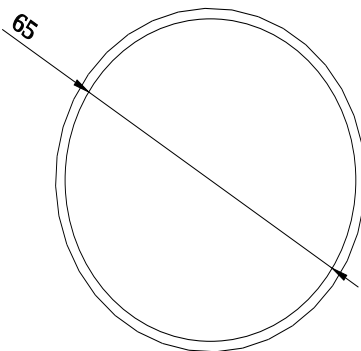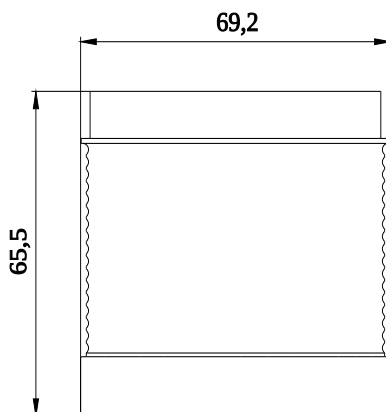

-P

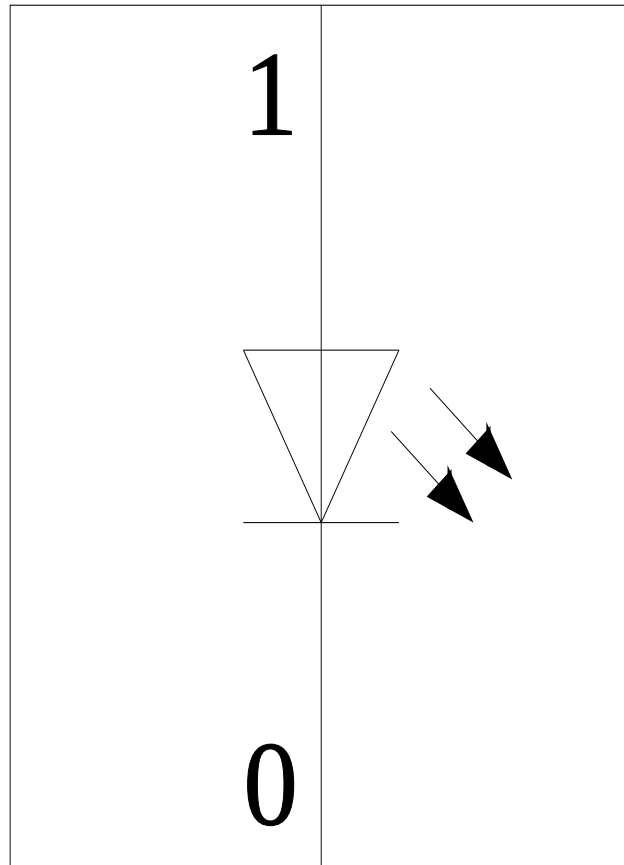

last modified:

7/15/2026 