

LED, base BA15d, red, 115 V AC, accessory for signaling columns, with diameter 50 mm and 70 mm



Figure similar

product brand name		SIRIUS	
product designation		LED	
General technical data			
type of voltage of the operating voltage		AC	
operating voltage		115 V	
• 1 at AC at 50 Hz rated value			
• 1 at AC at 60 Hz rated value		115 V	
relative positive tolerance of the operating voltage		10 %	
relative negative tolerance of the operating voltage		-15 %	
reference code according to EN 61346-2		P	
Lamp			
type of light source		LED	
light intensity		2.88 cd	
design of the reflection body		Drum lens	
socket design		BA 15d	
Enclosure			
height		45 mm	
width		20 mm	
outer diameter of the signal column element		70 mm	
color		red	
Ambient conditions			
ambient temperature during operation		-20 ... +60 °C	
Environmental footprint			
Environmental Product Declaration(EPD)		Yes	
Siemens eco profile (SEP)		Siemens EcoTech	
Approvals Certificates			
General Product Approval		other	



[Confirmation](#)



EG-Konf.



[Confirmation](#)



Environment



Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8WD4448-6XB>

Cax online generator

<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD4448-6XB>


Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8WD4448-6XB>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=8WD4448-6XB&lang=en

-P

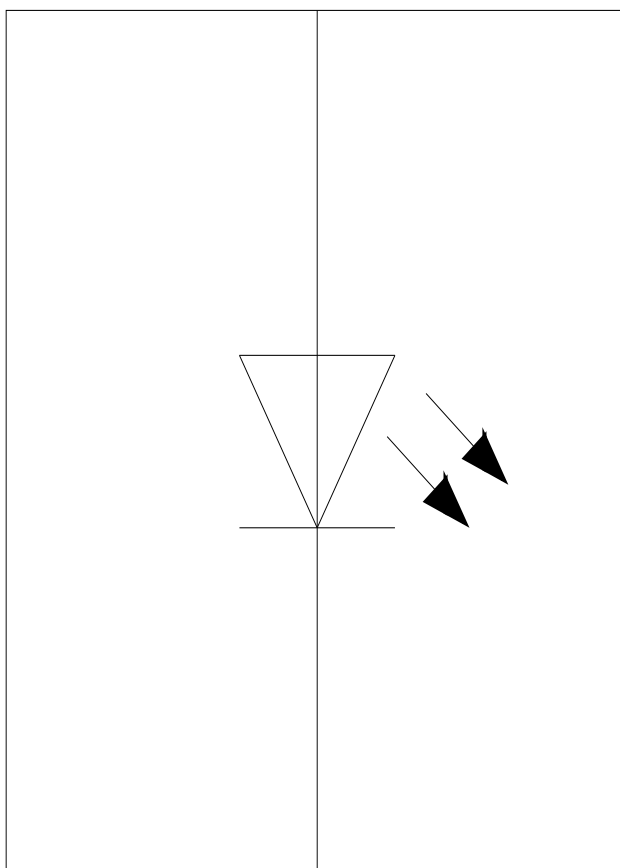

last modified:

7/15/2026