



activation & trip box TD300 incl. connecting cable 3VA - TD300 accessory for: 3VA6

Model	
product brand name	SETRON
product designation	Activation and trip box
accessories	Test device
General technical data	
mounting position	any
protection class IP	IP30
Mechanical Design	
number of circuit breakers / directly connectable	1
height	107 mm
width	76 mm
depth	25 mm
ambient temperature / during operation	
• minimum	-10 °C
• maximum	40 °C
ambient temperature / during storage	
• minimum	-40 °C
• maximum	50 °C
ambient temperature / during storage	
• minimum	-40 °C
• maximum	50 °C

Certificates		
General Product Approval	EMV	Test Certificates



[Miscellaneous](#)



[Type Test Certificates/Test Report](#)

Maritime application	other	Dangerous goods	Environment
----------------------	-------	-----------------	-------------



[Confirmation](#)

[Miscellaneous](#)

[Transport Information](#)

[Environmental Confirmations](#)

[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9977-0MA10>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9977-0MA10>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9977-0MA10

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

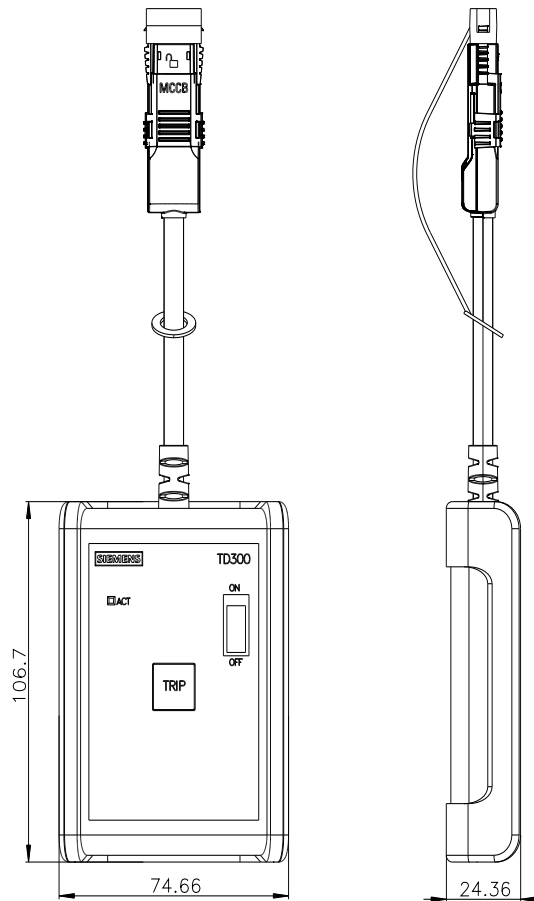

last modified:

4/3/2025

