

LED, base BA15d, clear, 24 V AC/DC, accessory for signaling columns, with diameter 50 mm and 70 mm



Figure similar

product brand name	SIRIUS		
product designation	LED		
General technical data			
type of voltage of the operating voltage	AC/DC		
operating voltage			
• 1 at DC rated value			
• 1 at AC at 50 Hz rated value			
• 1 at AC at 60 Hz rated value			
relative positive tolerance of the operating voltage	10 %		
relative negative tolerance of the operating voltage	-15 %		
consumed current maximum	15 mA		
reference code according to EN 61346-2	P		
Lamp			
type of light source	LED		
light intensity	1.4 cd		
socket design	BA 15d		
Enclosure			
height	45 mm		
width	20 mm		
outer diameter of the signal column element	70 mm		
color	clear		
Ambient conditions			
ambient temperature during operation	-20 ... +60 °C		
Approvals Certificates			
General Product Approval		other	Environment



[Confirmation](#)



Environment

[Environmental Con-
firmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8WD4428-6XE>

Cax online generator

<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD4428-6XE>


Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8WD4428-6XE>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=8WD4428-6XE&lang=en

-P

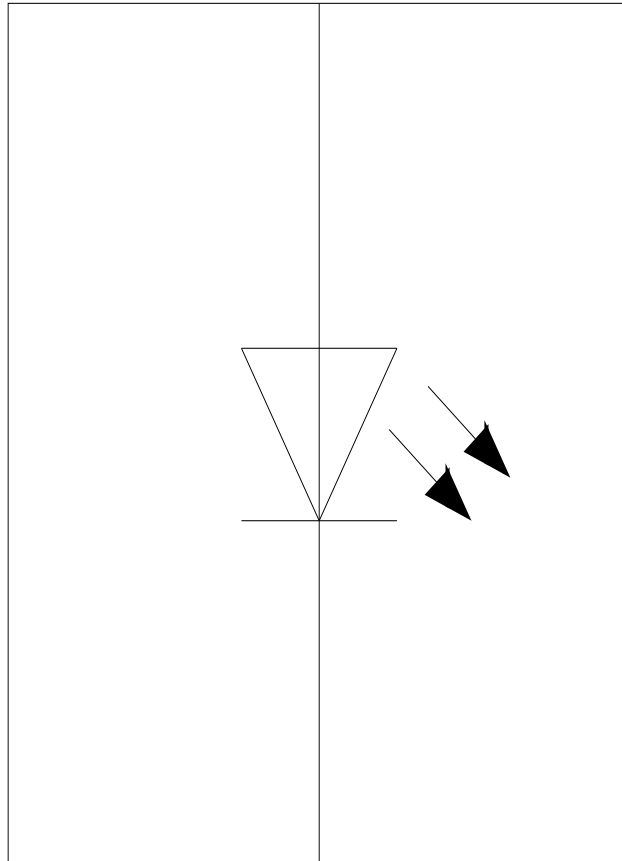

last modified:

4/1/2025 