

LED, base BA15d, yellow, 115 V AC, accessory for signaling columns, with diameter 50 mm and 70 mm



Figure similar

product brand name	SIRIUS			
product designation	LED			
General technical data				
type of voltage of the operating voltage	AC			
operating voltage				
• 1 at AC at 50 Hz rated value				115 V
• 1 at AC at 60 Hz rated value				115 V
relative positive tolerance of the operating voltage	10 %			
relative negative tolerance of the operating voltage	-15 %			
reference code according to EN 61346-2	P			
Lamp				
type of light source	LED			
light intensity	0.9 cd			
socket design	BA 15d			
Enclosure				
height	45 mm			
width	20 mm			
outer diameter of the signal column element	70 mm			
color	yellow			
Ambient conditions				
ambient temperature during operation	-20 ... +60 °C			
Approvals Certificates				
General Product Approval		other	Environment	



[Confirmation](#)



Environment

[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8WD4448-6XD>

Cax online generator

<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD4448-6XD>


Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8WD4448-6XD>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=8WD4448-6XD&lang=en

-P

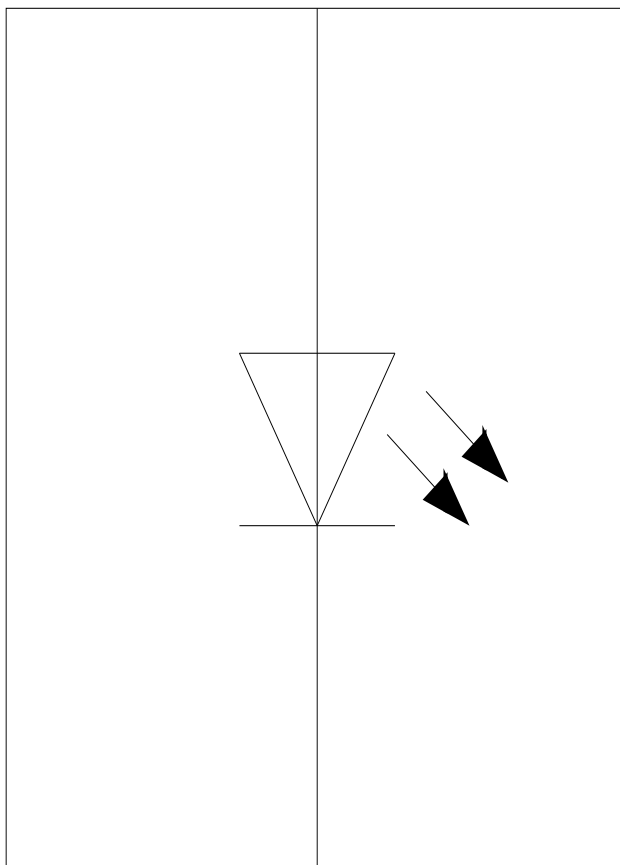

last modified:

4/1/2025 