



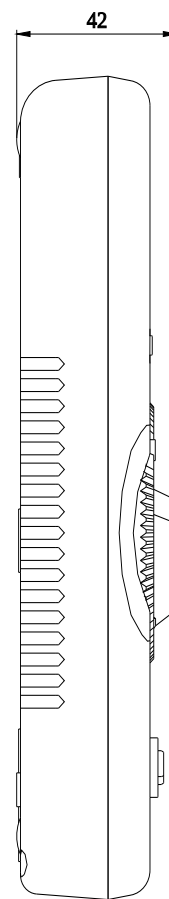

AS-Interface Addressing unit V3.0 for setting the addresses of AS-i slave modules Input/output test and further functions AS-i specification V3.0 M12 connection socket with addressing cable 1.5 m (M12 connector/hollow plug) with batteries (4 x 1.5 V LR6)

General technical data			
design of the product		AS-Interface addressing unit	
other information		storage temperature without batteries	
Ambient conditions			
ambient temperature			
• during operation	°C	0 ... 55	
• during storage	°C	-20 ... +55	
Mechanical data			
width	mm	84	
height	mm	195	
depth	mm	35	
Certificates/ approvals			
General Product Approval	EMV	Maritime application	other
			
	EG-Konf.		
		PRC	
other	Dangerous goods	Environment	
Confirmation	Transport Information	Environmental Confirmations	

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875
Information for data generation and storage https://support.industry.siemens.com/cs/ww/en/view/109995012
Information- and Downloadcenter (Catalogs, Brochures,...) https://www.siemens.com/ic10
Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RK1904-2AB02
Cax online generator https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RK1904-2AB02
Service&Support (Manuals, Certificates, Characteristics, FAQs,...) https://support.industry.siemens.com/cs/ww/en/ps/3RK1904-2AB02
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...) https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RK1904-2AB02&lang=en

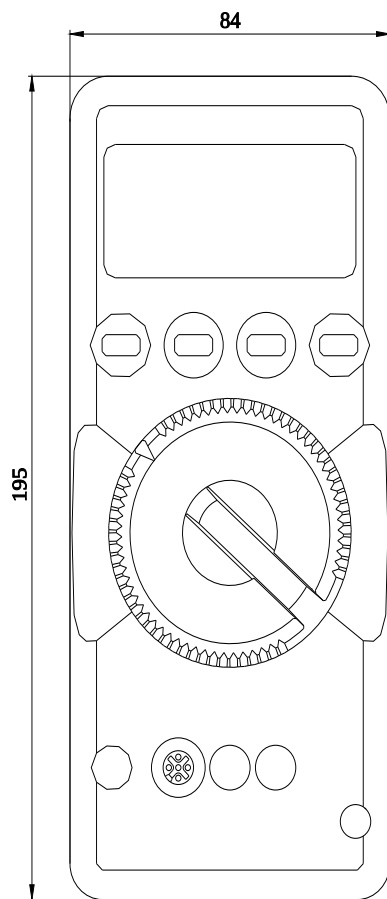

last modified:

11/20/2025 