



Molded-plastic enclosure for surface mounting Degree of protection IP55 with N and PE terminal 72 mm with metric cable gland No UL/CSA approval

|                          |                                               |
|--------------------------|-----------------------------------------------|
| product brand name       | SIRIUS                                        |
| product category         | Enclosure                                     |
| product designation      | Molded-plastic enclosure for surface mounting |
| design of the product    | Assembly                                      |
| product type designation | 3RV19                                         |

General technical data

|                                         |            |
|-----------------------------------------|------------|
| product function EMERGENCY OFF function | No         |
| protection class IP of the enclosure    | IP55       |
| Substance Prohibittance (Date)          | 07/01/2006 |
| Net Weight                              | 0.33 kg    |
| material of the enclosure               | plastic    |

Installation/ mounting/ dimensions

|        |        |
|--------|--------|
| height | 155 mm |
| width  | 105 mm |
| depth  | 89 mm  |

Approvals Certificates

|                          |                   |                      |
|--------------------------|-------------------|----------------------|
| General Product Approval | Test Certificates | Maritime application |
|--------------------------|-------------------|----------------------|



[Special Test Certificate](#)

[Type Test Certificates/Test Report](#)



|                      |       |
|----------------------|-------|
| Maritime application | other |
|----------------------|-------|



[Miscellaneous](#)

[Confirmation](#)

|       |         |             |
|-------|---------|-------------|
| other | Railway | Environment |
|-------|---------|-------------|



[Special Test Certificate](#)

[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RV1913-1DA00>

Cax online generator


<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RV1913-1DA00>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RV1913-1DA00>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

[https://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=3RV1913-1DA00&lang=en](https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RV1913-1DA00&lang=en)

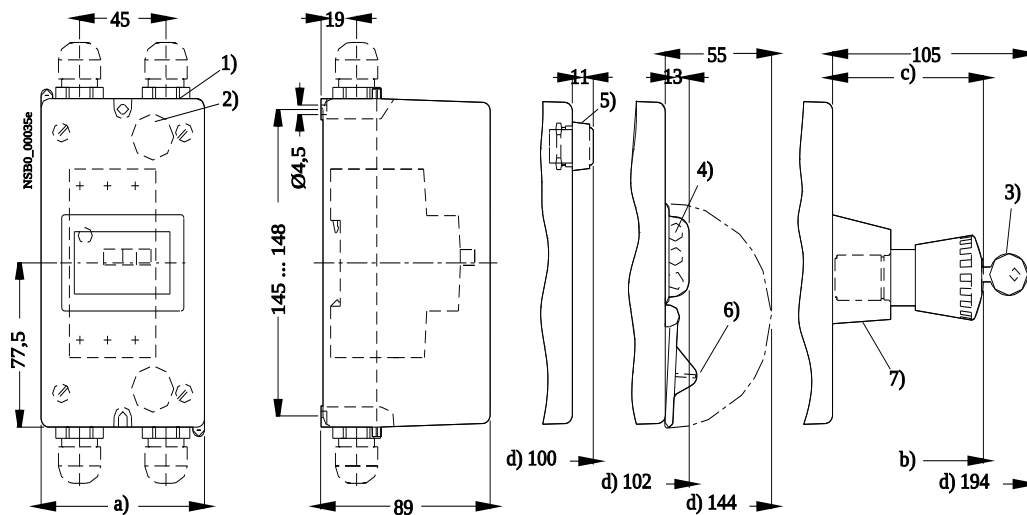

- 1) Knock-outs for M25 cable glands.
- 2) Knock-outs for rear cable entry M20.
- 3) With safety lock.
- 4) Max. shackle diameter for padlock 8 mm.
- 5) 3RV19 03-5 indicator light.
- 6) 3RV19 13-6B locking device.
- 7) 3RV19 13-7 EMERGENCY-STOP mushroom button.

- a) 3RV19 13-1CA00: 85 mm,  
3RV19 13-1DA00: 105 mm.
- b) With EMERGENCY-STOP mushroom button:  
- 3RV19 13-7D: 153 mm,  
- 3RV19 13-7E: 173 mm.  
Dimensions refer to mounting surface.
- b) With EMERGENCY-STOP mushroom button:  
- 3RV19 13-7D: 64 mm,  
- 3RV19 13-7E: 84 mm.
- d) Dimensions refer to mounting surface.

last modified:

10/18/2025