

USB type A 3.0 port, 22 mm, metal shiny, silver



|                                                        |                     |
|--------------------------------------------------------|---------------------|
| product brand name                                     | SIRIUS ACT          |
| product designation                                    | USB Type A port     |
| design of the product                                  | USB 3.0             |
| product type designation                               | 3SU1                |
| product line                                           | Metal, shiny, 22 mm |
| Actuator                                               |                     |
| outer diameter of the actuating element                | 29.45 mm            |
| General technical data                                 |                     |
| protection class IP                                    | IP65                |
| Substance Prohibittance (Date)                         | 10/01/2014          |
| Net Weight                                             | 46 g                |
| Ambient conditions                                     |                     |
| ambient temperature                                    |                     |
| • during operation                                     | 70 ... -25 °C       |
| • during storage and transport                         | -40 ... +80 °C      |
| Environmental footprint                                |                     |
| Environmental Product Declaration (EPD)                | Yes                 |
| global warming potential [CO2 eq] total                | 0.593 kg            |
| global warming potential [CO2 eq] during manufacturing | 0.625 kg            |
| global warming potential [CO2 eq] during operation     | 0.235 kg            |
| global warming potential [CO2 eq] after end of life    | -0.267 kg           |
| Installation/ mounting/ dimensions                     |                     |
| shape of the installation opening                      | round               |
| mounting diameter                                      | 22.3 mm             |
| mounting height                                        | 11.7 mm             |
| installation width                                     | 29.45 mm            |
| installation depth                                     | 28.35 mm            |
| Accessories                                            |                     |
| material of accessory                                  | Metal               |
| color of accessory                                     | Silver              |
| Approvals Certificates                                 |                     |
| General Product Approval                               | Test Certificates   |



[Type Test Certificates/Test Report](#)

Maritime application

other



[Confirmation](#)

## Environment



Siemens  
EcoTech



[Environmental Con-  
firmations](#)

## Further information

### Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

### Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

### Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

### Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3SU1950-0GA80-0AA0>

### Cax online generator


<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3SU1950-0GA80-0AA0>

### Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3SU1950-0GA80-0AA0>

### Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

[https://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=3SU1950-0GA80-0AA0&lang=en](https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3SU1950-0GA80-0AA0&lang=en)

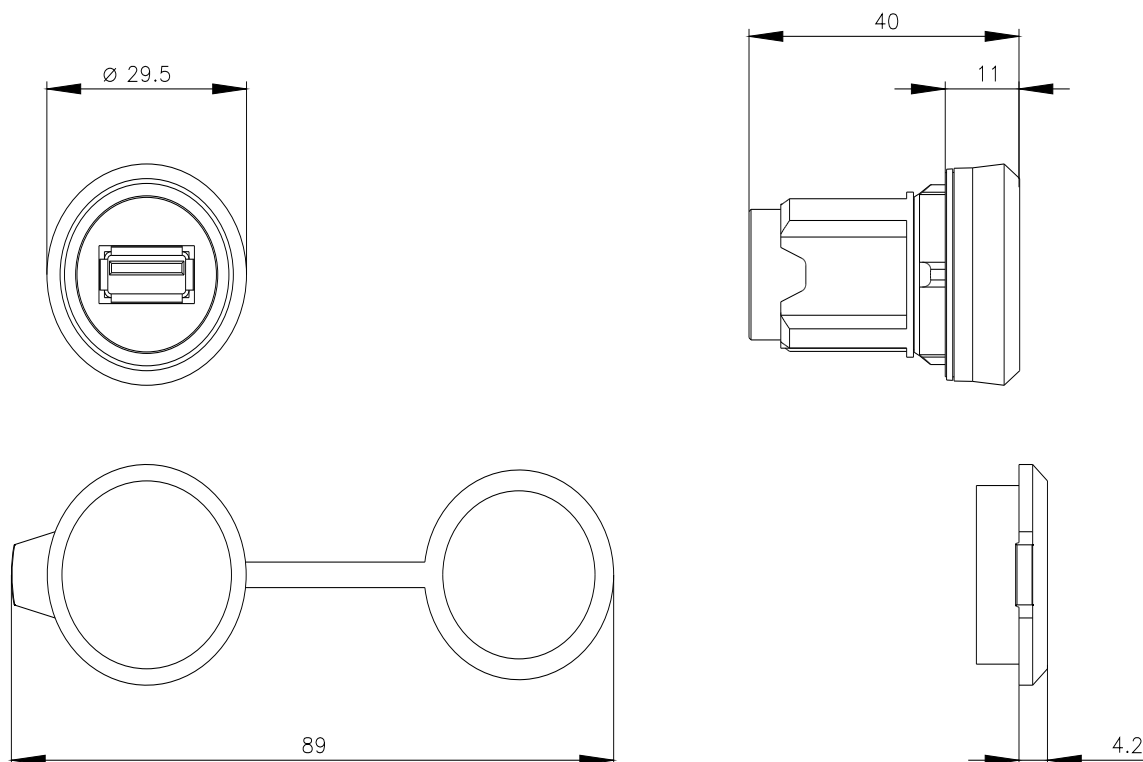

last modified:

4/17/2025