

stand-alone assembly support for 3RU21/3RB30/3RB31/3RR2 Size S0 Stand-alone installation Main circuit: Spring-type terminal Auxiliary circuit: --

product brand name	SIRIUS
product category	Terminal support
product designation	individual mount
product type designation	3RU29
General technical data	
size of overload relay	S0
protection class IP on the front • according to IEC 60529	IP20
Substance Prohibittance (Date)	10/01/2009
Net Weight	0.086 kg
Ambient conditions	
ambient temperature • during operation • during storage	-20 ... +70 °C -50 ... +80 °C
Electrical Safety	
protection class IP on the front according to IEC 60529	IP20
touch protection on the front according to IEC 60529	finger-safe, for vertical contact from the front
Installation/ mounting/ dimensions	
fastening method	screw and snap-on mounting onto 35 mm DIN rail
height	114 mm
width	45 mm
depth	76 mm
Connections/ Terminals	
type of electrical connection • for main current circuit	spring-loaded terminals
type of connectable conductor cross-sections • for main contacts — solid — stranded — finely stranded with core end processing • for AWG cables for main contacts	1x (1 ... 10 mm²) 1x (1 ... 10 mm²) 1 ... 6 mm² 1x (18 ... 8)
Approvals Certificates	
General Product Approval	Test Certificates



[Type Test Certificates/Test Report](#)

Test Certificates	Maritime application
-------------------	----------------------

[Special Test Certificate](#)



Maritime application	other	Environment
----------------------	-------	-------------



[Confirmation](#)

[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RU2926-3AC01>

Cax online generator


<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RU2926-3AC01>


Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RU2926-3AC01>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RU2926-3AC01&lang=en

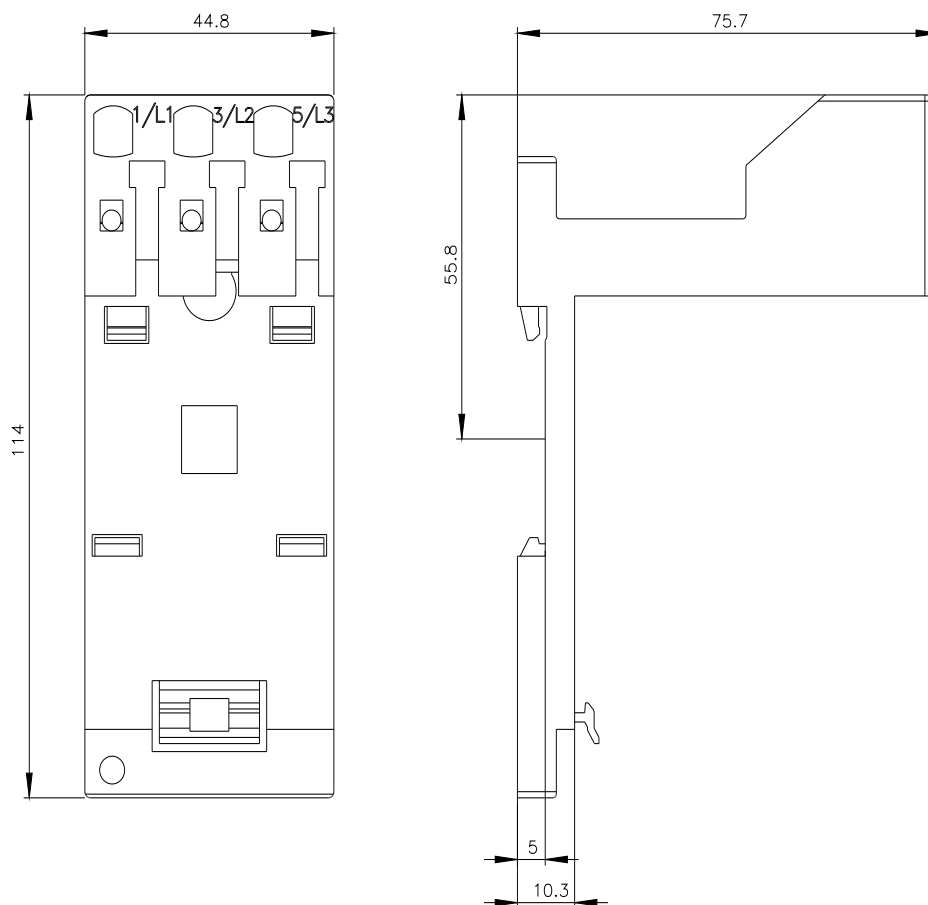

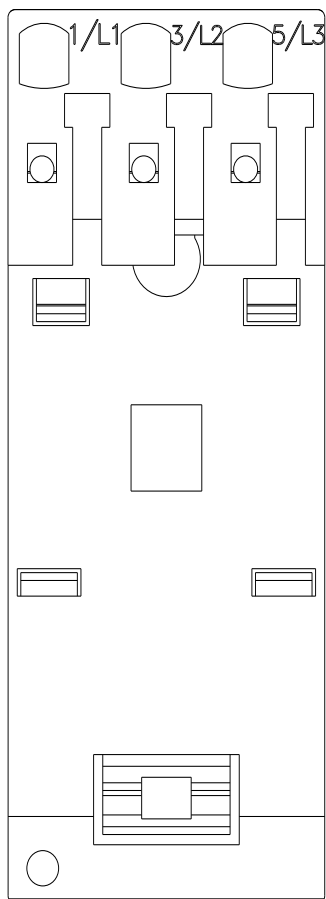

1/L1

3/L2

5/L3