


AS-i cable, shaped for external auxiliary voltage 24 V black, pure, oil-resistant 2 x 1.5 mm², 1 km, on drum consists of 1000 m cable Shipbuilding approval

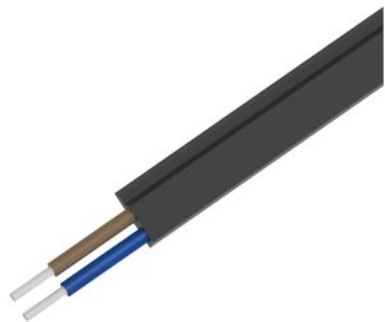

General technical data

design of the product	AS-Interface shaped cables
operating voltage rated value	300 V

Mechanical data

bending radius	
• for permanently laid cable minimum permissible	12 mm
• with moving cable minimum permissible	24 mm

Certificates/ approvals

General Product Approval	other	Environment
--------------------------	-------	-------------



[Confirmation](#)

[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information for data generation and storage
<https://support.industry.siemens.com/cs/ww/en/view/109995012>
Information- and Downloadcenter (Catalogs, Brochures,...)
<https://www.siemens.com/ic10>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RX9026-0AA00>
Cax online generator
<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RX9026-0AA00>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/3RX9026-0AA00>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)
https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RX9026-0AA00&lang=en

last modified: 11/19/2025