



Coupling M8 with connection cable, 5 m long for M8 connector 4-pole, for 3SE66 magnetically-operated switch

General technical data	
product brand name	SIRIUS
product designation	Coupling, M8 socket, for 3SE66
operational current at 40 °C rated value	4 A
operating voltage rated value	30 V
number of poles	4
wire length of connection cable	5 m
ambient temperature during operation	-25 ... +85 °C
type of electrical connection	connector M8
color coding of the core	Pin 1 = BN, Pin 2 = WH, Pin 3 = BU, Pin 4 = BK
overvoltage category	2
degree of pollution	3
protection class IP	IP67
material	
• of the contact	CuSn
• of contact coating	Au
• of contact main body	PUR
Certificates/ approvals	
General Product Approval	other




[Confirmation](#)


Environment

[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information for data generation and storage
<https://support.industry.siemens.com/cs/ww/en/view/109995012>
Information- and Downloadcenter (Catalogs, Brochures,...)
<https://www.siemens.com/ic10>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3SX5601-3GA05>

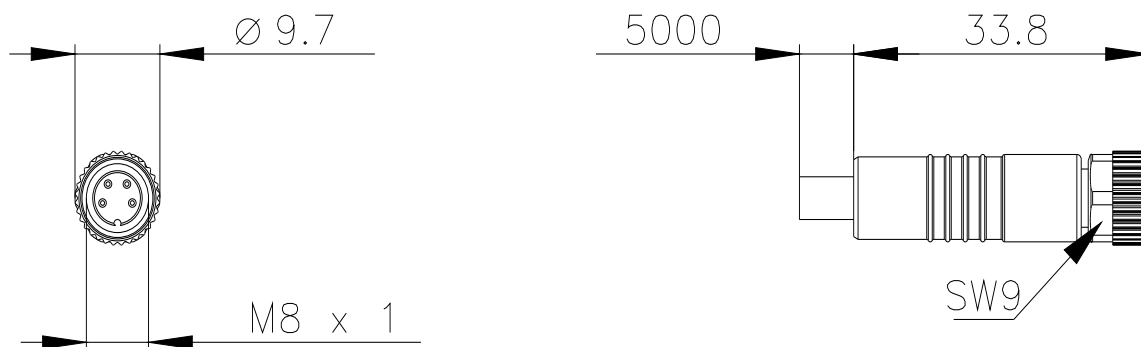

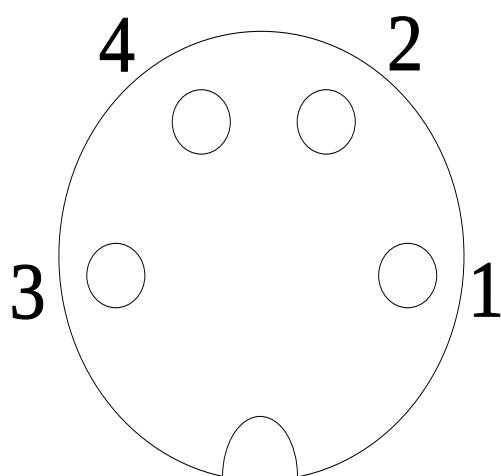

1	BN = Brown
2	WH = White
3	BU = Blue
4	BK = Black

last modified:

4/2/2025 