



Flashlight element, with integrated LED, clear, 115 V AC, Diameter 70 mm

|                                                      |                              |
|------------------------------------------------------|------------------------------|
| product brand name                                   | SIRIUS                       |
| product designation                                  | Repeated-flash light element |
| design of the product                                | including light sources      |
| General technical data                               |                              |
| type of voltage of the operating voltage             | AC                           |
| operating voltage                                    |                              |
| • 1 at AC at 50 Hz rated value                       | 115 V                        |
| • 1 at AC at 60 Hz rated value                       | 115 V                        |
| relative positive tolerance of the operating voltage | 10 %                         |
| relative negative tolerance of the operating voltage | -10 %                        |
| consumed current maximum                             | 25 mA                        |
| reference code according to EN 61346-2               | P                            |
| Lamp                                                 |                              |
| product component light source                       | Yes                          |
| type of light source                                 | LED                          |
| service life of LED                                  | 100 000 h                    |
| design of the optical signal                         | blinklight                   |
| light intensity                                      | 1.04 cd                      |
| light intensity                                      | 0.73 ... 1.52 cd             |
| flashing frequency                                   | 1 Hz                         |
| Enclosure                                            |                              |
| height                                               | 65.5 mm                      |
| width                                                | 70 mm                        |
| outer diameter of the signal column element          | 70 mm                        |
| material                                             | PC                           |
| color                                                | clear                        |
| fastening method                                     | Bayonet                      |
| protection class IP                                  | IP65                         |
| Ambient conditions                                   |                              |
| ambient temperature during operation                 | -20 ... +50 °C               |
| Approvals Certificates                               |                              |
| General Product Approval                             | other                        |

[Confirmation](#)



|       |             |
|-------|-------------|
| other | Environment |
|-------|-------------|



#### Further information

**Information on the packaging**

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

**Information for data generation and storage**

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

**Information- and Downloadcenter (Catalogs, Brochures,...)**

<https://www.siemens.com/ic10>

**Industry Mall (Online ordering system)**

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8WD4440-5BE>

**Cax online generator**



<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD4440-5BE>

**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**


<https://support.industry.siemens.com/cs/ww/en/ps/8WD4440-5BE>

**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)**

[https://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=8WD4440-5BE&lang=en](https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=8WD4440-5BE&lang=en)

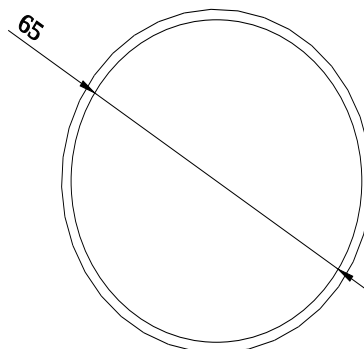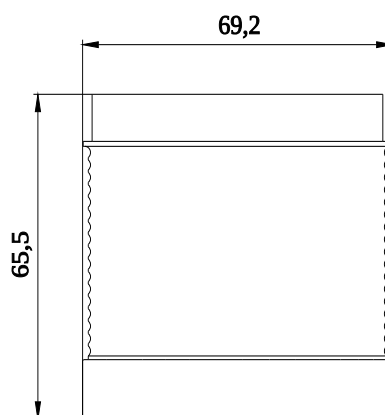

**-P**

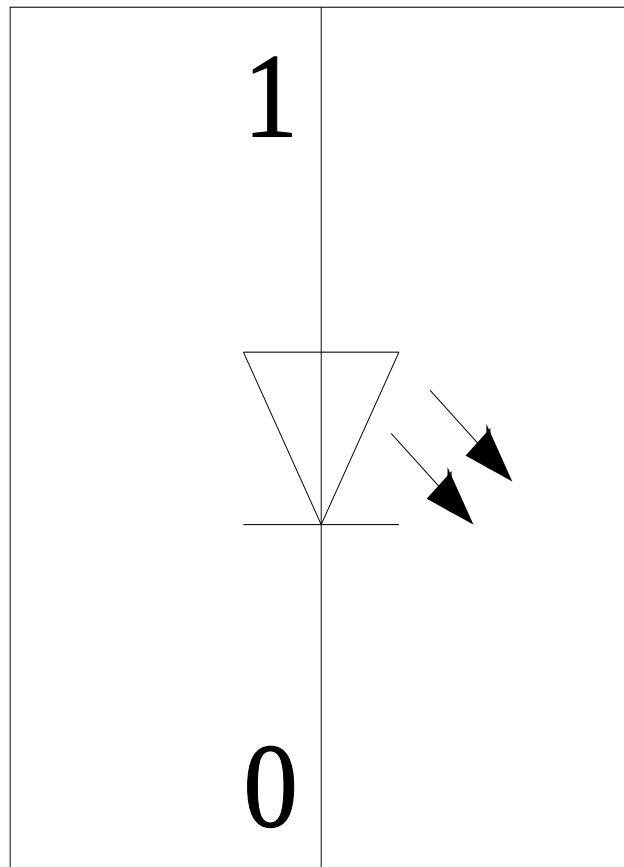

last modified:

4/1/2025 